

RTU Ball Swivel



FEATURES

Swivels up to 15°

SPECIFICATIONS


Finish: Electrogalvanized

Material: Steel

Table 1/1

Catalog Number	Article Number	E-Number	Screw Diameter (Sc)	Screw Length (L)	Height (H)	Static Load
RTUM8L15	583600		8	15mm	66 mm	2500N
RTUM10	583590	3532729	10	18mm	75 mm	2500N
RTUM10L18	583610		10	18mm	85 mm	2500N

DIAGRAMS

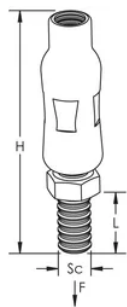

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

