


STRC CU Strap Clamp for Copper Tube

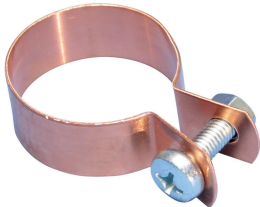

FEATURES

Includes fasteners, screw and nut

SPECIFICATIONS

Material: Copper

Table 1/2


Catalog Number	Article Number	E-Number	Outer Diameter (OD)	Width (W)	Thickness (T)	Screw Diameter (Sc)
STRC028CU	574210	3535104	28 mm	15 mm	0.6 mm	6
STRC022CU	574200	3535103	22 mm	15 mm	0.6 mm	6
STRC018CU	574190	3535102	18 mm	15 mm	0.6 mm	6
STRC015CU	574180	3535101	15 mm	15 mm	0.6 mm	6
STRC012CU	574170	3535099	12 mm	15 mm	0.6 mm	6

Table 2/2

Catalog Number	Article Number	E-Number	Screw Length (L)
STRC028CU	574210	3535104	16mm

Catalog Number	Article Number	E-Number	Screw Length (L)
STRC022CU	574200	3535103	16mm
STRC018CU	574190	3535102	16mm
STRC015CU	574180	3535101	16mm
STRC012CU	574170	3535099	16mm

DIAGRAMS

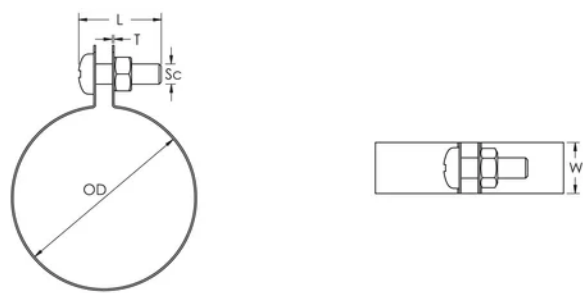

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

