

Strut Beam Clamp with U-Bolt



FEATURES

Complete with U-bolt and nuts

Requires installation in pairs

SPECIFICATIONS

Table 1/3

Catalog Number	Article Number	E-Number	Material	Finish	Strut Type	Rod Size (RS)
ZTA601HD	387701	3532968	Steel	Hot-Dip Galvanized	A (41 x 41 mm), C (21 x 41 mm), CC (41 x 41 mm)	10
ZTA601S6	387710	3535822	Stainless Steel 316 (EN 1.4401)		A (41 x 41 mm), C (21 x 41 mm), CC (41 x 41 mm)	10
ZTA602HD	388006	3535823	Steel	Hot-Dip Galvanized	A (41 x 41 mm), AA (83 x 41 mm), D (62 x 41 mm), E (83 x 41 mm)	10
ZTA603HD	388066	3535824	Steel	Hot-Dip Galvanized	DD (124 x 41 mm)	10

Table 2/3

Catalog Number	Article Number	E-Number	Flange Thickness (FT)	Width (W)	Thickness (T)	A
ZTA601HD	387701	3532968	18 mm Max	80 mm	6 mm	24 mm
ZTA601S6	387710	3535822	18 mm Max	80 mm	6 mm	24 mm
ZTA602HD	388006	3535823	18 mm Max	80 mm	6 mm	24 mm
ZTA603HD	388066	3535824	18 mm Max	80 mm	6 mm	24 mm


Table 3/3

Catalog Number	Article Number	E-Number	B	C	Static Load
ZTA601HD	387701	3532968	45 mm	95 mm	5000N
ZTA601S6	387710	3535822	45 mm	110 mm	5000N
ZTA602HD	388006	3535823	45 mm	140 mm	5000N
ZTA603HD	388066	3535824	45 mm	180 mm	5000N

ADDITIONAL PRODUCT DETAILS

Static Load is based on one pair of Strut Beam Clamps.

DIAGRAMS

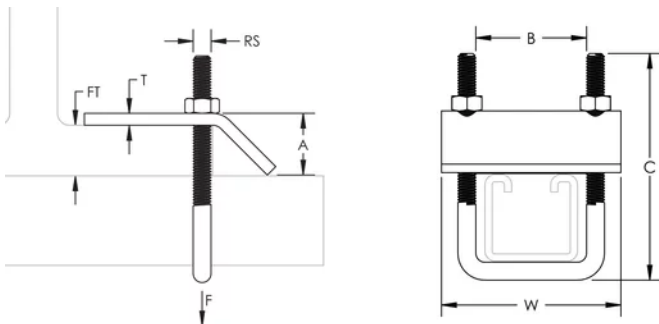

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

