

Strut Nut without Spring



FEATURES

Used to create metal frames with nVent CADDY Eristrut channels

SPECIFICATIONS

Static Load Safety Factor: 3:1

Table 1/2

Catalog Number	Article Number	E-Number	Material	Finish	Rod Size (RS)	Thickness (T)
NUTM6S6	315140	1342860	Stainless Steel 316 (EN 1.4401)		6	6 mm
NUTM6HD	315000	1340550	Steel	Hot-Dip Galvanized	6	6 mm
NUTM8S6	315150	3535417	Stainless Steel 316 (EN 1.4401)		8	6 mm
NUTM8HD	315010	1340551	Steel	Hot-Dip Galvanized	8	6 mm
NUTM8EG	315015	3435668	Steel	Electrogalvanized	8	6 mm
NUTM6EG	314995	1342859	Steel	Electrogalvanized	6	6 mm

CatalogNumber	Article Number	E-Number	Material	Finish	Rod Size (RS)	Thickness (T)
NUTM10HD	315020	3435669	Steel	Hot-Dip Galvanized	10	8 mm
NUTM10S6	315160	1342864	Stainless Steel 316 (EN 1.4401)		10	8 mm
NUTM12EG	315035	3435673	Steel	Electrogalvanized	12	8 mm
NUTM12HD	315030	1340553	Steel	Hot-Dip Galvanized	12	8 mm
NUTM12S6	315170	3535047	Stainless Steel 316 (EN 1.4401)		12	8 mm
NUTM10EG	315025	3435671	Steel	Electrogalvanized	10	8 mm
NUTM16EG	315036	3435674	Steel	Electrogalvanized	16	11.7 mm
NUTM16HD	315037	3535489	Steel	Hot-Dip Galvanized	16	11.7 mm



Table 2/2

Catalog Number	Article Number	E-Number	Torque (TQ)
NUTM6S6	315140	1342860	12 N·m
NUTM6HD	315000	1340550	12 N·m
NUTM8S6	315150	3535417	28 N·m
NUTM8HD	315010	1340551	28 N·m
NUTM8EG	315015	3435668	28 N·m
NUTM6EG	314995	1342859	12 N·m
NUTM10HD	315020	3435669	55 N·m
NUTM10S6	315160	1342864	55 N·m
NUTM12EG	315035	3435673	55 N·m

Catalog Number	Article Number	E-Number	Torque (TQ)
NUTM12HD	315030	1340553	55 N·m
NUTM12S6	315170	3535047	55 N·m
NUTM10EG	315025	3435671	55 N·m
NUTM16EG	315036	3435674	125 N·m
NUTM16HD	315037	3535489	125 N·m

Pull-Out Strength				
Part Number	Channel Type	Channel Thickness		
		2,5 mm	2 mm	1,5 mm
NUTM6xx	A, C	2000 N	2000 N	2000 N
	D, E	2000 N	-	-
NUTM8xx	A, C	3330 N	3330 N	3330 N
	D, E	3330 N	-	-
NUTM10xx	A, C	4890 N	4440 N	4440 N
	D, E	4890 N	-	-
NUTM12xx	A, C	4890 N	4660 N	4440 N
	D, E	3670 N	-	-
NUTM12Txx	A	5670 N	5050 N	4440 N
	D, E	4250 N	-	-
NUTM16xx	A	5670 N	4660 N	4440 N
	D, E	4250 N	-	-

DIAGRAMS

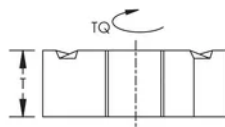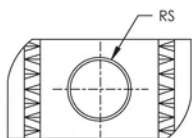

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

