

TBHK Trapezoidal Deck Hanger



CERTIFICATIONS



FEATURES

Requires separate cross bolt and nut

Use TDHP perforation tool to punch hole in decking

SPECIFICATIONS

Table 1/3

Catalog Number	Article Number	E-Number	Material	Finish	A	B
TBHK	597581	1319924	Steel	Electrogalvanized	97 mm	91.5 mm

Table 2/3


Catalog Number	Article Number	E-Number	C	Thickness (T)	Hole Size 1 (HS1)	Hole Size 2 (HS2)
TBHK	597581	1319924	25 mm	2.5 mm	10.5 mm	5 mm

Table 3/3

Catalog Number	Article Number	E-Number	Hole Size 3 (HS3)
TBHK	597581	1319924	10 1/2mm

Ceiling Thickness	Static Load F
0,63 mm - 0,70 mm	600 N
0,71 mm - 0,80 mm	700 N
0,81 mm - 1,00 mm	800 N
1,01 mm - 1,20 mm	1000 N
1,21 mm - 1,50 mm	1200 N
> 1,50 mm	1500 N

DIAGRAMS

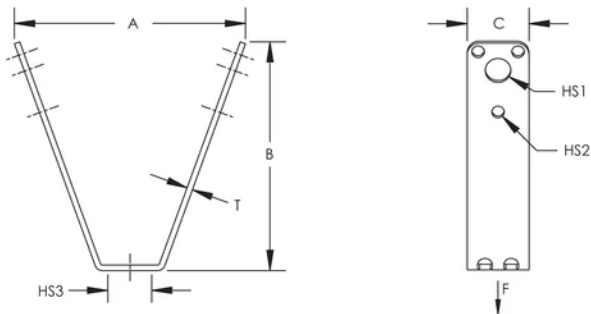

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

