

TBHKM Trapezoidal Deck Hanger with Fixed Nut



CERTIFICATIONS



FEATURES

Requires separate cross bolt and nut

Use TDHP perforation tool to punch hole in decking

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2


Catalog Number	Article Number	E-Number	Rod Size (RS)	A	B	C
TBHKM8	597582	3435979	8	97 mm	91.5 mm	25 mm
TBHKM10	597583	3532711	10	97 mm	91.5 mm	25 mm

Table 2/2

Catalog Number	Article Number	E-Number	Thickness (T)	Hole Size 1 (HS1)	Hole Size 2 (HS2)	Certifications
TBHKM8	597582	3435979	2.5 mm	10.5 mm	5 mm	VdS G4060082, ITB
TBHKM10	597583	3532711	2.5 mm	10.5 mm	5 mm	VdS G4060082, FM Approved, Pipe Hanger Components, ITB

Ceiling Thickness	Static Load F
0,63 mm - 0,70 mm	600 N
0,71 mm - 0,80 mm	700 N
0,81 mm - 1,00 mm	800 N
1,01 mm - 1,20 mm	1000 N
1,21 mm - 1,50 mm	1200 N
> 1,50 mm	1500 N

DIAGRAMS

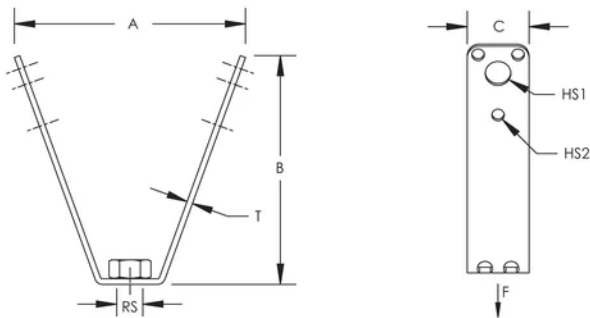

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

