

TDH Trapezoidal Deck Hanger



CERTIFICATIONS



FEATURES

Easy install

If thread connection is required, use square nut THHM and snap in

Use TDHP perforation tool to punch hole in decking

SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	E-Number	Material	Finish	Hole Size 1 (HS1)	Hole Size 2 (HS2)
TDH	179920	1341300	Spring Steel	nVent CADDY Armour	6.8 mm	14 mm

Table 2/2

Catalog Number	Article Number	E-Number	Hole Size 3 (HS3)	D
TDH	179920	1341300	10 1/2mm	50 mm Max

Ceiling Thickness	Static Load F
0,63 mm - 0,70 mm	600 N
0,71 mm - 0,80 mm	700 N
0,81 mm - 1,00 mm	800 N
1,01 mm - 1,20 mm	1000 N
1,21 mm - 1,50 mm	1200 N
> 1,50 mm	1500 N

DIAGRAMS

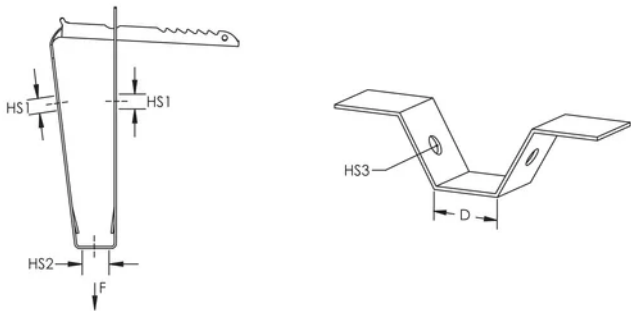

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

