

Thread Install Rod Hanger with Angle Bracket



FEATURES

Suspends threaded rod from horizontal structures such as laminated wood or concrete beams, joists, ceilings and walls

SPECIFICATIONS

Finish: nVent CADDY Armour;Pregalvanized

Material: Spring Steel;Steel

Table 1/2

Catalog Number	Article Number	E-Number	Hole Size 1 (HS1)	Hole Type 1	Hole Size 2 (HS2)	Hole Type 2
M8TIB	174940	3435482	7 mm	Plain	8 mm	Threaded
M6TIB	174850	1319482	7 mm	Plain	6 mm	Threaded
M10TIB	175030	3435491	7 mm	Plain	10 mm	Threaded

Table 2/2

Catalog Number	Article Number	E-Number	Static Load
M8TIB	174940	3435482	700N
M6TIB	174850	1319482	700N


Catalog Number	Article Number	E-Number	Static Load
M10TIB	175030	3435491	700N

ADDITIONAL PRODUCT DETAILS

Loads indicated are for nVent CADDY Fasteners only.

Method of attachment to structure must be evaluated separately.

DIAGRAMS

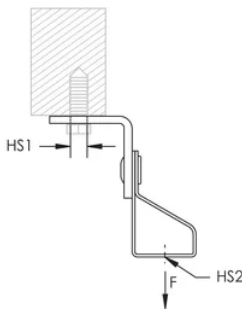

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

