

U-Bolt



FEATURES

Complete with 4 nuts

SPECIFICATIONS

Table 1/2

Catalog Number	Article Number	E-Number	Material	Finish	Outer Diameter (OD)	NB/DN
UB4N23M6S6	599485		Stainless Steel 316 (EN 1.4401)		23 mm	10
UB4N027M8S6	597615	3535312	Stainless Steel 316 (EN 1.4401)		27 mm	20
UB4N30M6EG	599405		Steel	Electrogalvanized	30 mm	20
UB4N30M6S6	599490		Stainless Steel 316 (EN 1.4401)		30 mm	20
UB4N36M8EG	599410		Steel	Electrogalvanized	36 mm	25
UB4N36M8S6	599495		Stainless Steel 316 (EN 1.4401)		36 mm	25
UB4N042M8	599150	3535331	Steel	Electrogalvanized	42 mm	32

CatalogNumber	Article Number	E-Number	Material	Finish	Outer Diameter (OD)	NB/DN
UB4N46M6S6	599510		Stainless Steel 316 (EN 1.4401)		46 mm	32
UB4N46M6EG	599415		Steel	Electrogalvanized	42 mm	32
UB4N049M8	599160	3535332	Steel	Electrogalvanized	49 mm	40
UB4N049M8S6	597645	3535315	Stainless Steel 316 (EN 1.4401)		49 mm	40
UB4N52M8S6	599515		Stainless Steel 316 (EN 1.4401)		52 mm	40
UB4N52M8EG	599420		Steel	Electrogalvanized	49 mm	40
UB4N042M8S6	597635	3535314	Stainless Steel 316 (EN 1.4401)		42 mm	32
UB4N64M8S6	599520		Stainless Steel 316 (EN 1.4401)		65 mm	50
UB4N64M8EG	599425		Steel	Electrogalvanized	60 mm	50
UB4N076M8S6	597665	3535317	Stainless Steel 316 (EN 1.4401)		76 mm	65
UB4N74M8EG	599430		Steel	Electrogalvanized	74 mm	65
UB4N74M8S6	599525		Stainless Steel 316 (EN 1.4401)		74 mm	65
UB4N090M10	599190	3533004	Steel	Electrogalvanized	90 mm	80
UB4N090M8S6	599357	3535318	Stainless Steel 316 (EN 1.4401)		90 mm	80
UB4N94M10EG	599440		Steel	Electrogalvanized	94 mm	80
UB4N94M10S6	599530		Stainless Steel 316 (EN 1.4401)		94 mm	80

CatalogNumber	Article Number	E-Number	Material	Finish	Outer Diameter (OD)	NB/DN
UB4N114M10	599200	3533005	Steel	Electrogalvanized	114 mm	100
UB4N114M8S6	599348	3535352	Stainless Steel 316 (EN 1.4401)		114 mm	100
UB4N118M10EG	599445		Steel	Electrogalvanized	118 mm	100
UB4N118M10S6	599535		Stainless Steel 316 (EN 1.4401)		118 mm	100
UB4N140M8	599337	3535339	Steel	Electrogalvanized	140 mm	125
UB4N140M8S6	599350	3535341	Stainless Steel 316 (EN 1.4401)		140 mm	125
UB4N146M12EG	599450		Steel	Electrogalvanized	146 mm	125
UB4N146M12S6	599540		Stainless Steel 316 (EN 1.4401)		146 mm	125
UB4N160M8	599338	3535342	Steel	Electrogalvanized	160 mm	
UB4N160M8S6	599351	3535343	Stainless Steel 316 (EN 1.4401)		160 mm	
UB4N168M12EG	599455		Steel	Electrogalvanized	168 mm	
UB4N168M12S6	599545		Stainless Steel 316 (EN 1.4401)		168 mm	
UB4N168M14	599240	3533006	Steel	Electrogalvanized	168 mm	150
UB4N168M8S6	599352	3535345	Stainless Steel 316 (EN 1.4401)		168 mm	150

CatalogNumber	Article Number	E-Number	Material	Finish	Outer Diameter (OD)	NB/DN
UB4N172M16EG	599460		Steel	Electrogalvanized	172 mm	150
UB4N172M16S6	599550		Stainless Steel 316 (EN 1.4401)		172 mm	150
UB4N219M10	599341	3535346	Steel	Electrogalvanized	219 mm	200
UB4N219M10S6	599354	3535483	Stainless Steel 316 (EN 1.4401)		219 mm	200
UB4N219M16	599250	3533007	Steel	Electrogalvanized	219 mm	200
UB4N224M12S6	599555		Stainless Steel 316 (EN 1.4401)		224 mm	200
UB4N224M16EG	599470		Steel	Electrogalvanized	224 mm	200
UB4N273M16	599260	3533008	Steel	Electrogalvanized	273 mm	250
UB4N278M16EG	599475		Steel	Electrogalvanized	278 mm	250
UB4N278M16S6	599560		Stainless Steel 316 (EN 1.4401)		278 mm	250
UB4N323M10	599343	3535348	Steel	Electrogalvanized	323 mm	300
UB4N323M10S6	599356	3535353	Stainless Steel 316 (EN 1.4401)		323 mm	300
UB4N329M16EG	599480		Steel	Electrogalvanized	345 mm	300
UB4N329M16S6	599565		Stainless Steel 316 (EN 1.4401)		345 mm	300


Table 2/2

Catalog Number	Article Number	E-Number	Rod Size (RS)	Height (H)
UB4N23M6S6	599485		M6	50 mm
UB4N027M8S6	597615	3535312	M8	58 mm
UB4N30M6EG	599405		M6	60 mm
UB4N30M6S6	599490		M6	60 mm
UB4N36M8EG	599410		M8	70 mm
UB4N36M8S6	599495		M8	70 mm
UB4N042M8	599150	3535331	M8	76 mm
UB4N46M6S6	599510		M6	80 mm
UB4N46M6EG	599415		M8	80 mm
UB4N049M8	599160	3535332	M8	78 mm
UB4N049M8S6	597645	3535315	M8	78 mm
UB4N52M8S6	599515		M8	90 mm
UB4N52M8EG	599420		M8	90 mm
UB4N042M8S6	597635	3535314	M8	76 mm
UB4N64M8S6	599520		M8	100 mm
UB4N64M8EG	599425		M8	100 mm
UB4N076M8S6	597665	3535317	M8	118 mm
UB4N74M8EG	599430		M8	120 mm

Catalog Number	Article Number	E-Number	Rod Size (RS)	Height (H)
UB4N74M8S6	599525		M8	120 mm
UB4N090M10	599190	3533004	M10	125 mm
UB4N090M8S6	599357	3535318	M8	125 mm
UB4N94M10EG	599440		M10	140 mm
UB4N94M10S6	599530		M10	140 mm
UB4N114M10	599200	3533005	M10	166 mm
UB4N114M8S6	599348	3535352	M8	166 mm
UB4N118M10EG	599445		M10	140 mm
UB4N118M10S6	599535		M10	165 mm
UB4N140M8	599337	3535339	M8	197 mm
UB4N140M8S6	599350	3535341	M8	197 mm
UB4N146M12EG	599450		M12	200 mm
UB4N146M12S6	599540		M12	200 mm
UB4N160M8	599338	3535342	M8	214 mm
UB4N160M8S6	599351	3535343	M8	214 mm
UB4N168M12EG	599455		M12	220 mm
UB4N168M12S6	599545		M12	220 mm
UB4N168M14	599240	3533006	M14	224 mm

Catalog Number	Article Number	E-Number	Rod Size (RS)	Height (H)
UB4N168M8S6	599352	3535345	M8	224 mm
UB4N172M16EG	599460		M16	240 mm
UB4N172M16S6	599550		M16	240 mm
UB4N219M10	599341	3535346	M10	286 mm
UB4N219M10S6	599354	3535483	M10	286 mm
UB4N219M16	599250	3533007	M16	286 mm
UB4N224M12S6	599555		M12	295 mm
UB4N224M16EG	599470		M16	295 mm
UB4N273M16	599260	3533008	M16	331 mm
UB4N278M16EG	599475		M16	350 mm
UB4N278M16S6	599560		M16	350 mm
UB4N323M10	599343	3535348	M10	389 mm
UB4N323M10S6	599356	3535353	M10	389 mm
UB4N329M16EG	599480		M16	400 mm
UB4N329M16S6	599565		M16	400 mm

DIAGRAMS

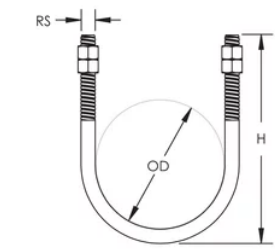

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

