

PEMSA Wire Basket Tray L Bracket

Data Solutions



CERTIFICATIONS



FEATURES

Easy to use, quick connect feature

Ideal for typical wall and channel installations

IEC 61537 load rating and earthing compliant

SPECIFICATIONS

Finish: Electrogalvanized


Material: Steel

Table 1/1

Catalog Number	Article Number	Length (L)	Width (W)	Height (H)	Static Load	Certifications
----------------	----------------	------------	-----------	------------	-------------	----------------

WBT100LBRKT	820200	170mm	54mm	138mm	588N	CE, CADDY EU WBT BRT, DoP, CADDY EU WBT, ANOR EU WTB B S
WBT150LBRKT	820210	220mm	54mm	138mm	588N	CE, CADDY EU WBT BRT, ANOR EU WTB B S, DoP, CADDY EU WBT
WBT200LBRKT	820220	270mm	54mm	138mm	588N	
WBT300LBRKT	820230	370mm	54mm	138mm	373N	UKCA, CADDY EU WBT B, DoP, CADDY EU WBT, CE, CADDY EU WBT BRT, ANOR EU WTB B S
WBT400LBRKT	820240	470mm	54mm	138mm	275N	CE, CADDY EU WBT BRT, DoP, CADDY EU WBT, ANOR EU WTB B S, UKCA, CADDY EU WBT B

DIAGRAMS

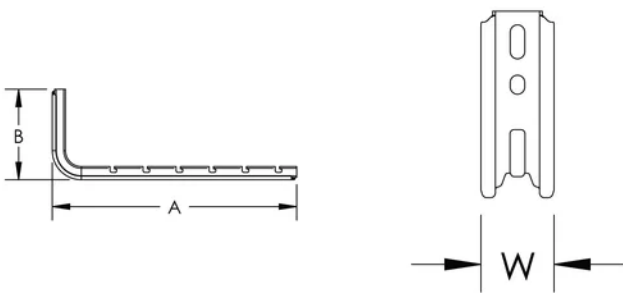

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE