


Aluminium Terminal Box, HALP

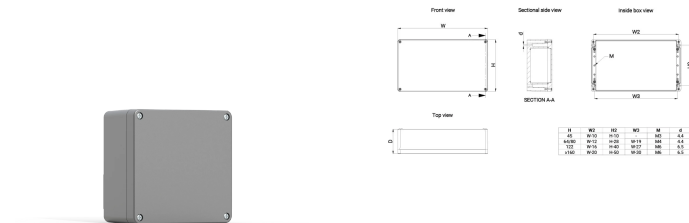

The aluminium terminal box range, HALP, with a IP 66, 67 protection degree, is available off the shelf in many different sizes. The HALP range is well suited for indoor and outdoor environments thanks to excellent corrosion resistance. Water and dust are prevented from entering the terminal box, thus eliminating the risk for component failure, and with that, unnecessary downtime.

INDUSTRY STANDARDS

CE UKCA

EAC

GOST

IP

FEATURES

Material: Aluminium alloy EN AC-47100.

Gasket: Standard supply fitted with a polyurethane gasket. Silicone, neoprene and EPDM gaskets are available on request.

Temperature resistance: -30 °C to +80 °C.

Protection: IP 66, 67, IK 09, 08 for HALP050503GE.

Finish: RAL 7001.

Approvals: CE, GOST. For cULus_UL Listed approvals, please contact our sales department.

Delivery: Body and cover are manufactured from aluminum, cover screws are made of stainless steel.

SPECIFICATIONS


Material: Aluminum
Finish: Powder Coated
Color Code: RAL 7001
Color: Silver Grey

Table 1/1

Catalog Number	E-Number	Height (H)	Width (W)	Depth (D)	Body Thickness	Cover Thickness
HALP050503GE	1270179	45mm	50mm	30mm	3mm	2mm
HALP080806GE	1270183	80mm	74mm	57mm	3.5mm	2.5mm
HALP081306GE	1270184	80mm	124mm	57mm	3.5mm	2.6mm
HALP081806GE	1270185	80mm	175mm	57mm	3.5mm	2.5mm
HALP082506GE	1270186	80mm	249mm	57mm	3.5mm	2.5mm
HALP060604GE	1270180	64mm	57mm	36mm	3.5mm	3mm
HALP061004GE	1270181	64mm	98mm	36mm	3.5mm	3mm
HALP061504GE	1270182	64mm	150mm	36mm	3.5mm	3mm
HALP121208GE	1270187	122mm	121mm	80mm	4.1mm	3.7mm
HALP123608GE	1270191	122mm	359mm	80mm	4.1mm	3.7mm
HALP161609GE	1270192	160mm	160mm	90mm	4.1mm	3.7mm
HALP163609GE	1270194	160mm	359mm	90mm	4.1mm	3.7mm
HALP233311GE	1270197	230mm	329mm	110mm	4.1mm	3.7mm
HALP233318GE	1270198	230mm	329mm	180mm	4.5mm	3.7mm
HALP234011GE	1270199	230mm	400mm	110mm	4.1mm	3.7mm
HALP121209GE	1270188	122mm	121mm	90mm	4.1mm	4mm

Catalog Number	E-Number	Height (H)	Width (W)	Depth (D)	Body Thickness	Cover Thickness
HALP122208GE	1270189	122mm	219mm	80mm	4mm	4mm
HALP122209GE	1270190	122mm	219mm	90mm	4mm	4mm
HALP162609GE	1270193	160mm	260mm	90mm	4mm	4mm
HALP165609GE	1270195	160mm	560mm	90mm	4mm	4mm
HALP232011GE	1270196	230mm	199mm	110mm	4.1mm	4.1mm
HALP236011GE	1286000	230mm	599mm	110mm	4mm	4mm

DIAGRAMS

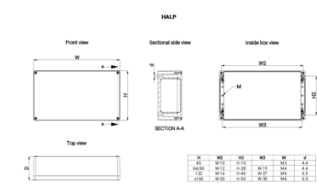

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE