

Cable Anchorage Glands For Wall Mounted Enclosures, CAG



This two component cable gland can be mounted on a wide range of enclosures. It secures the cable into position, and eliminates any external strains.

FEATURES

Description: Two-component grommet with membrane seal and cable anchorage. The installation does not require tools, it is self-adjusting to its surrounding wall thickness and click-fixed in place. Because of its compact design it only extends 5.7 mm outside the enclosure on which it is mounted. The "pushout" membrane is a permanent seal until it is penetrated by a cable or pipe. Suitable for holes in materials of 0.7 to 3 mm thickness.

Material: TPE and polyamide 66, halogen free.

Temperature resistance: -20 °C to +125 °C.

Finish: RAL 7035.

Protection: IP 67, 65, waterproof.


Pack quantity: 50 pieces.

SPECIFICATIONS

Color: Light Gray
Material: Plastic
Color Code: RAL 7035
Finish: Smooth

Table 1/1						
Catalog Number	E-Number	Height (H)	Width (W)	Depth (D)	Height (H)	Diameter (Ø)
CAG20	1304019	19.5mm	30.7mm	30.7mm	17 – 20mm	34 – 37mm
CAG25	1304020	19.7mm	35.7mm	35.7mm	17 – 20mm	39 – 42mm

DIAGRAMS

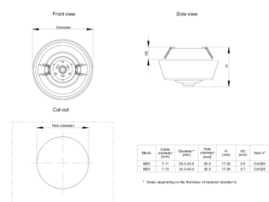

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE