


EL LED Enclosure Light

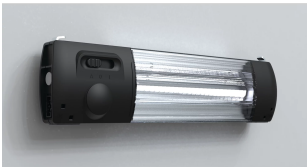

An LED light specially designed for nVent HOFFMAN enclosures. Tool-free assembly reduces the assembly time. Simple through wiring based on a plug and play system.

FEATURES

Description: LED enclosure light specially designed for nVent HOFFMAN enclosures. Fast and tool-free assembly thanks to a latching hook system designed to fit the 25mm hole pattern on nVent HOFFMAN enclosures. May be fitted horizontally or vertically.

Please be advised that when using the clamp mechanism to mount these lights, they cannot be installed on the top rail of ProLine and ProLine G2 cabinet frames.

SPECIFICATIONS

Color Temperature:	4000K
Color:	Black
Lamp Type:	LED
Light Color:	Neutral White
Material:	Plastic
Finish:	Smooth
Operating Temperature:	-20 to 55°C

Table 1/1

Catalog Number	E-Number	Height	Width	Depth	Socket Type	Light Output
EL1200D24V	3302997	76mm	315mm	48mm	NA	1200lm
EL1200M24V	3303004	76mm	315mm	48mm	NA	1200lm
EL1200DS	3302998	76mm	364mm	48mm	SCHUKO, Type F	1200lm
EL1200DS-BF	3302999	76mm	364mm	48mm	Type E	1200lm
EL1200DS-CH	3303000	76mm	364mm	48mm	Type J	1200lm
EL1200DS-GB	3303001	76mm	364mm	48mm	Type G	1200lm
EL1200DS-US	3303002	76mm	364mm	48mm	Type B	1200lm
EL1200M	3303003	76mm	315mm	48mm	NA	1200lm
EL1200MS	3303005	76mm	364mm	48mm	SCHUKO, Type F	1200lm
EL1200MS-BF	3303006	76mm	364mm	48mm	Type E	1200lm
EL1200MS-CH	3303007	76mm	364mm	48mm	Type J	1200lm
EL1200MS-GB	3303008	76mm	364mm	48mm	Type G	1200lm
EL1200MS-US	3303009	76mm	364mm	48mm	Type B	1200lm
EL900D	3303010	76mm	314mm	48mm	NA	900lm
EL900DS	3303011	76mm	364mm	48mm	SCHUKO, Type F	900lm

Catalog Number	E-Number	Height	Width	Depth	Socket Type	Light Output
EL900DS-BF	3303012	76mm	364mm	48mm	Type E	900lm
EL900DS-CH	3303013	76mm	364mm	48mm	Type J	900lm
EL900DS-GB	3303014	76mm	364mm	48mm	Type G	900lm
EL900DS-US		76mm	364mm	48mm	Type B	900lm

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE