


Inner Door, UID

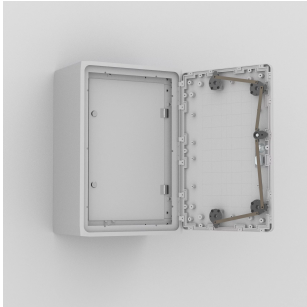

Displays and indicators can be mounted on a surface within the enclosure while covering other components, and preventing unauthorized access.

FEATURES

Description: For controls, meters, lamps, etc. Hinges can be mounted to allow left or right hand opening. Lock double-bit 3 mm insert. Distance between UID and enclosure door: 48 mm.

Material: Glass fibre reinforced polyester.

Finish: RAL 7035.

Protection: IP 20.

Delivery: 1 piece with mounting accessories.

A plain door to be mounted inside a wall mounted enclosure

Additional mounting surface providing two levels of access

Non authorized personnel have access to the controls on the inner door only

This accessory is often used in enclosures with glazed door

SPECIFICATIONS

- Material:

Glass Fiber Reinforced Polymer
- Color:

Light Gray
- Color Code:

RAL 7035
- Finish:

Smooth Matte

Table 1/1				
Catalog Number	E-Number	Height	Width	Quick Ship
UID5050	2519303	500mm	500mm	No
UID5075	2519304	500mm	750mm	No
UID10050	2519301	1000mm	500mm	No
UID7550	2519305	750mm	500mm	No
UID7575	2519306	750mm	750mm	No
UID10075	2519302	1000mm	750mm	No

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE