

Small ABS Terminal Box, DABP



The ABS terminal box range, DABP, with a IP 66, 67 protection degree, is available off the shelf in many different sizes. The DABP range is well suited for demanding environments, since water and dust are prevented from entering the terminal box, thus eliminating the risk for component failure, and with that unnecessary downtime.

INDUSTRY STANDARDS

CE
UKCA
GOST
IP

FEATURES

Description: ABS box, halogen-free, suitable for indoor use. Low UV radiation resistance.

Material: Body: ABS. Plain cover: ABS. Transparent cover: polycarbonate.

Gasket: Polyurethane gasket integrated in the box cover.

Temperature resistance: -40 °C to +60 °C.

Flammability: UL94 HB.

Protection: IP 66, 67 | IK 06 (-25 °C), IK 07 (+35 °C).

Finish: RAL 7035.

Delivery: Body, cover, cover screws manufactured from stainless steel, mounting screws and cover plugs made from polyamide.

Low UV radiation resistance

Polyurethane gasket integrated in the box cover

Temperature resistance: -40 °C to +60 °C

Flammability: UL94 HB

Body, cover, cover screws manufactured from stainless steel, mounting screws and cover plugs made from polyamide

SPECIFICATIONS

Material: ABS
Color: Light Gray
Finish: Smooth

Table 1/1


Catalog Number	E-Number	Height (H)	Width (W)	Depth (D)	Max Mounting Depth	Weight
DABP080806GE	1270104	80mm	82mm	86mm	42mm	0.1kg
DABP080809GE	1270106	80mm	82mm	56mm	72mm	0.1kg
DABP081206GE	1270108	80mm	120mm	56mm	42mm	0.15kg
DABP081209GE	1270110	80mm	120mm	86mm	72mm	0.2kg
DABP081606GE	1270112	80mm	160mm	56mm	42mm	0.2kg
DABP081609GE	1270114	80mm	160mm	86mm	72mm	0.2kg
DABP121206GE	1270116	120mm	122mm	56mm	42mm	0.2kg
DABP121209GE	1270118	120mm	122mm	86mm	72mm	0.25kg
DABP121609GE	1270120	120mm	160mm	91mm	77mm	0.35kg
DABP122009GE	1270122	120mm	200mm	86mm	72mm	0.35kg
DABP152008GE	1270124	150mm	200mm	76mm	62mm	0.4kg
DABP050504GE	1270100	53mm	55mm	36mm	27.5mm	0.5kg
DABP162409GE	1270126	160mm	240mm	91mm	77mm	0.55kg
DABP162412GE	1270128	160mm	240mm	121mm	107mm	0.7kg
DABP050704GE	1270102	53mm	65mm	36mm	25mm	0.8kg
DABP233009GE	1270130	230mm	300mm	86mm	72mm	0.85kg

Catalog Number	E-Number	Height (H)	Width (W)	Depth (D)	Max Mounting Depth	Weight
DABP233011GE	1270132	230mm	300mm	111mm	97mm	1 kg

ADDITIONAL PRODUCT DETAILS

Note: Terminal box, with polycarbonate transparent cover fitted, can be ordered by replacing GE with TE in the item number.

DIAGRAMS

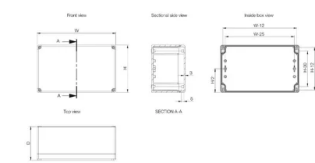

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE