


Metal Connection Kit, Cold-Applied

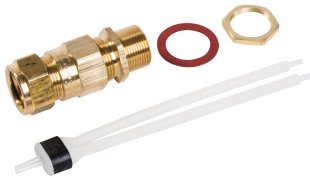

nVent RAYCHEM C25-100-METAL and C3/4-100-METAL are cold-applied metal connection kits for terminating all nVent RAYCHEM self-regulating and power-limiting industrial parallel heating cables to a metal or plastic junction box with internal earthing plate. C25-100-METAL for M25 entries, C3/4-100-METAL: for 3/4" NPT entries.

FEATURES

- Simple and fast to install
- Cold-applied: core sealing boot with non-curing sealant; no heat gun, no hot work permit needed
- One component for all nVent RAYCHEM industrial parallel heating cables
- Simplified design in hazardous area, integral part of system approval
- Reliable during long life: 10 year extended product warranty available, maintenance free

SPECIFICATIONS

Max Exposure Temperature:	180 °C
Connection Type:	Cold Applied
Model:	Connection to Junction Box

Table 1/1			
Catalog Number	Item Name	E-Number	Thread Size
1244-001350	C3/4-100-METAL-NP		3/4"
440588-000	C3/4-100-METAL	1038363	3/4"
875016-000	C25-100-METAL	1038364	M25 x 1.5
1244-002296	C25-100-METAL-NP		M25 x 1.5

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

Tel +1.800.545.6258

Fax +1.800.527.5703

thermal.info@nvent.com

Europe, Middle East, Africa

Tel +32.16.213.511

Fax +32.16.213.604

thermal.info@nvent.com

Asia Pacific

Tel +86.21.2412.1688

Fax +86.21.5426.3167

cn.thermal.info@nvent.com

Latin America

Tel +1.713.868.4800

Fax +1.713.868.2333

thermal.info@nvent.com

Our powerful portfolio of brands:

RAYCHEM PYROTENAX TRACER NUHEAT