


# Front Panel, Full Width, Slotted, Unshielded, for RatiopacPRO

Full-width front panel, slotted, unshielded.

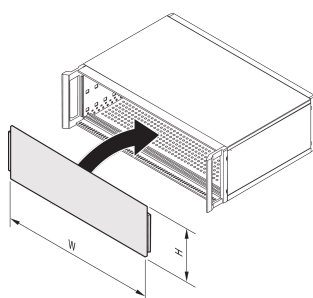

## CERTIFICATIONS



## FEATURES

Inserted between side panel and molded parts such as trim, 19" mounting bracket or handle

Front panels can also be used as rear panels

Fixes without screws (special horizontal rails cover the edges of the front panel and hold them in place)

Shielded (rear conductive); for a conductive connection with the case please order EMC sealing (stainless steel) separately

## SPECIFICATIONS

|                        |                      |
|------------------------|----------------------|
| <b>Depth (D):</b>      | 2.5mm                |
| <b>Material:</b>       | Aluminum             |
| <b>Finish:</b>         | Anodized; Passivated |
| <b>Accessory Type:</b> | Front panel          |
| <b>Product Type:</b>   | Front Panel          |

Table 1/2

| Catalog Number | Rack Height | Rack Width | Package Quantity | Front Finish | Rear Finish | Treated Edges |
|----------------|-------------|------------|------------------|--------------|-------------|---------------|
|----------------|-------------|------------|------------------|--------------|-------------|---------------|

|           |    |      |   |          |            |    |
|-----------|----|------|---|----------|------------|----|
| 34571-617 | 2U | 28HP | 1 | Anodized | Conductive | No |
| 34571-618 | 2U | 42HP | 1 | Anodized | Conductive | No |
| 34571-605 | 3U | 28HP | 1 | Anodized | Conductive | No |
| 34571-609 | 4U | 28HP | 1 | Anodized | Conductive | No |
| 34571-606 | 3U | 42HP | 1 | Anodized | Conductive | No |
| 34571-619 | 2U | 63HP | 1 | Anodized | Conductive | No |
| 34571-621 | 5U | 28HP | 1 | Anodized | Conductive | No |
| 34571-620 | 2U | 84HP | 1 | Anodized | Conductive | No |
| 34571-610 | 4U | 42HP | 1 | Anodized | Conductive | No |
| 34571-613 | 6U | 28HP | 1 | Anodized | Conductive | No |
| 34571-607 | 3U | 63HP | 1 | Anodized | Conductive | No |
| 34571-622 | 5U | 42HP | 1 | Anodized | Conductive | No |
| 34571-608 | 3U | 84HP | 1 | Anodized | Conductive | No |
| 34571-611 | 4U | 63HP | 1 | Anodized | Conductive | No |
| 34571-614 | 6U | 42HP | 1 | Anodized | Conductive | No |
| 34571-623 | 5U | 63HP | 1 | Anodized | Conductive | No |
| 34571-612 | 4U | 84HP | 1 | Anodized | Conductive | No |
| 34571-615 | 6U | 63HP | 1 | Anodized | Conductive | No |
| 34571-624 | 5U | 84HP | 1 | Anodized | Conductive | No |


|           |    |      |   |          |            |    |
|-----------|----|------|---|----------|------------|----|
| 34571-616 | 6U | 84HP | 1 | Anodized | Conductive | No |
|-----------|----|------|---|----------|------------|----|

Table 2/2

| Catalog Number | Height (H) | Width (W) | Quick Ship |
|----------------|------------|-----------|------------|
| 34571-617      | 84mm       | 141.9mm   | No         |
| 34571-618      | 84mm       | 213.2mm   | No         |
| 34571-605      | 128.4mm    | 141.9mm   | No         |
| 34571-609      | 172.9mm    | 141.9mm   | No         |
| 34571-606      | 128.4mm    | 213.2mm   | No         |
| 34571-619      | 84mm       | 319.7mm   | No         |
| 34571-621      | 217.3mm    | 141.9mm   | No         |
| 34571-620      | 84mm       | 426.4mm   | No         |
| 34571-610      | 172.9mm    | 213.2mm   | No         |
| 34571-613      | 261.8mm    | 141.9mm   | No         |
| 34571-607      | 128.4mm    | 319.7mm   | No         |
| 34571-622      | 217.3mm    | 213.2mm   | No         |
| 34571-608      | 128.4mm    | 426.4mm   | No         |
| 34571-611      | 172.9mm    | 319.7mm   | No         |
| 34571-614      | 261.8mm    | 213.2mm   | No         |
| 34571-623      | 217.3mm    | 319.7mm   | No         |
| 34571-612      | 172.9mm    | 426.4mm   | No         |

| Catalog Number | Height (H) | Width (W) | Quick Ship |
|----------------|------------|-----------|------------|
| 34571-615      | 261.8mm    | 319.7mm   | No         |
| 34571-624      | 217.3mm    | 426.4mm   | No         |
| 34571-616      | 261.8mm    | 426.4mm   | No         |

## DIAGRAMS

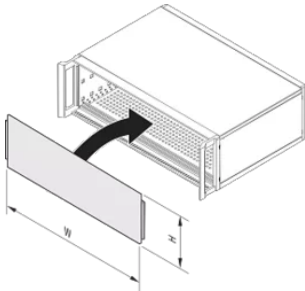

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**