


Plug-In Unit U-Profile Front Panel for Handle Form 1

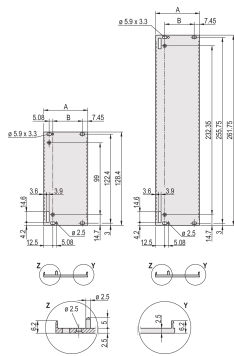

U-profile front panel. Enables the assembly of form 1 trapezoid form extraction handle. The front panel can be shielded with a textile gasket.

CERTIFICATIONS



FEATURES

Al profile, front anodized, rear conductive

Front panel, U-profile, shieldable

Alignment pin pressed-in, stainless steel

SPECIFICATIONS

Material:	Aluminum
Finish:	Anodized; Passivated
Accessory Type:	Front panel
Product Type:	Front Panel
Type:	Front Panel with Handle (PIU)
EMC Shielding:	No (Retrofittable)

Table 1/3

Catalog Number	Rack Height	Rack Width	Package Quantity	Handle Type	Mounting	Front Finish
----------------	-------------	------------	------------------	-------------	----------	--------------

30848-461	3U	4HP	1	Trapezoid, Type 1	Screw-on Front	Anodized
30848-463	3U	6HP	1	Trapezoid, Type 1	Screw-on Front	Anodized
30848-465	3U	8HP	1	Trapezoid, Type 1	Screw-on Front	Anodized
30848-468	6U	4HP	1	Trapezoid, Type 1	Screw-on Front	Anodized
30848-466	3U	10HP	1	Trapezoid, Type 1	Screw-on Front	Anodized
30848-467	3U	12HP	1	Trapezoid, Type 1	Screw-on Front	Anodized
30848-470	6U	6HP	1	Trapezoid, Type 1	Screw-on Front	Anodized
30848-472	6U	8HP	1	Trapezoid, Type 1	Screw-on Front	Anodized
30848-473	6U	10HP	1	Trapezoid, Type 1	Screw-on Front	Anodized
30848-474	6U	12HP	1	Trapezoid, Type 1	Screw-on Front	Anodized

Table 2/3						
Catalog Number	Rear Finish	Treated Edges	Complies With	Depth (D)	Height (H)	Width (W)
30848-461	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	128.4mm	20mm
30848-463	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	128.4mm	30.1mm
30848-465	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	128.4mm	40.3mm
30848-468	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	20mm
30848-466	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	128.4mm	50.5mm
30848-467	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	128.4mm	60.6mm

CatalogNumber	Rear Finish	Treated Edges	Complies With	Depth (D)	Height (H)	Width (W)
30848-470	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	30.1mm
30848-472	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	40.3mm
30848-473	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	50.5mm
30848-474	Conductive	No	IEC 60297-3-101, IEEE 1101.1/11	2.5mm	261.8mm	60.6mm

Table 3/3

Catalog Number	Quick Ship
30848-461	No
30848-463	No
30848-465	No
30848-468	No
30848-466	No
30848-467	No
30848-470	No
30848-472	No
30848-473	No
30848-474	No

ADDITIONAL PRODUCT DETAILS

Please order EMC profile seal separately.

Please take into consideration that deliveries may be carried out in the stated SPQs (SPQ, e.g. 5 pieces, 10 pieces, 50 pieces, etc.). Differing order quantities (e.g. 2 pieces) may be changed to the next possible delivery quantity = Standard Pack Quantity.

DIAGRAMS



WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

All locations
+1.763.422.2661
Chat with us:
nvent.com/schroff

Europe

Straubenhardt, Germany
+49.7082.794.0
Betschdorf, France
+33.3.88.90.64.90
Warsaw, Poland
+48.22.209.98.35
Assago, Italy
+39.02.932.7141
Chat with us:
nvent.com/schroff

Asia

Shanghai, China
+86.21.2412.6943
Qingdao, China
+86.532.8771.6101
Singapore
+65.6768.5800
Shin-Yokohama, Japan
+81.45.476.0271
Chat with us:
nvent.com/schroff

Middle East & India

Dubai, United Arab Emirates
+971.4.378.1700
Bangalore, India
+91.80.6715.2001
Istanbul, Turkey
+90.216.250.7374
Chat with us:

nvent.com/schroff



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE