

300M Universal Beam Clamp



CERTIFICATIONS



FEATURES

Universal beam clamp for standard beams

Structural attachment (with infinite adjustment) to top or bottom flange of metal beams to support hanger rod

Including set screw and lock nut

SPECIFICATIONS

Material: Cast Iron
Finish: Electrogalvanized
Hole Type: Plain

Table 1/2

Catalog Number	Article Number	Hole Size (HS)	Flange Thickness (FT)	A	Torque (TQ)	Static Load
30009MM	389500	9 mm	18 mm Max	21 mm	14 N·m Min	1200N
30011MM	389510	11 mm	20 mm Max	23 mm	14 N·m Min	2500N


CatalogNumber	Article Number	Hole Size (HS)	Flange Thickness (FT)	A	Torque (TQ)	Static Load
30013MM	389520	13 mm	26 mm Max	35 mm	14 N·m Min	3500N
30017MM	389505	17 mm	28 mm Max	30 mm	14 N·m Min	5500N

Table 2/2		
Catalog Number	Article Number	Certifications
30009MM	389500	VdS G4005005, ITB
30011MM	389510	VdS G4005005, FM Approved, Pipe Hanger Components, ITB
30013MM	389520	FM Approved, Pipe Hanger Components, VdS G4913044, ITB
30017MM	389505	ITB, FM Approved, Pipe Hanger Components, VdS G4031026

ADDITIONAL PRODUCT DETAILS

Setscrew must be tightened and torqued onto the sloped side of the I-beam.

DIAGRAMS

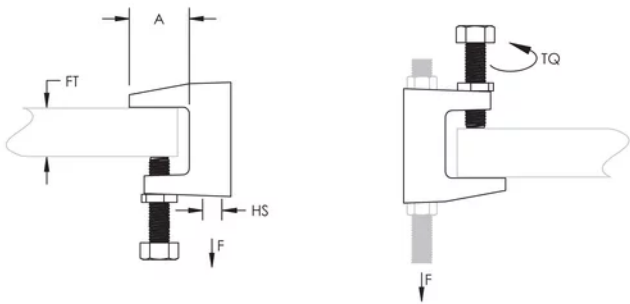

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

