

ADJ Clamp for PVC Pipe



FEATURES

Adjustable suspension of horizontal and vertical pipe services

Double bolted

SPECIFICATIONS

Color: White

Table 1/2

Catalog Number	Finish	NB/DN	Outer Diameter (OD)	Rod Size (RS)	Height (H)	Width (W)
ADJ040PVCHD G	Hot-Dip Galvanized	40	43 mm	M8	102 mm	20 mm
ADJ040PVCPP C	Polyester	40	43 mm	M8	102 mm	20 mm
ADJ050PVCHD G	Hot-Dip Galvanized	50	55 mm	M8	114 mm	20 mm
ADJ050PVCPP C	Polyester	50	55 mm	M8	114 mm	20 mm
ADJ065PVCHD G	Hot-Dip Galvanized	65	69 mm	M8	128 mm	20 mm


CatalogNumber	Finish	NB/DN	Outer Diameter (OD)	Rod Size (RS)	Height (H)	Width (W)
ADJ065PVCPP C	Polyester	65	69 mm	M8	128 mm	20 mm
ADJ080PVCHD G	Hot-Dip Galvanized	80	82 mm	M8	141 mm	20 mm
ADJ100PVCHD G	Hot-Dip Galvanized	100	110 mm	M8	169 mm	20 mm
ADJ100PVCPP C	Polyester	100	110 mm	M8	169 mm	20 mm
ADJ150PVCHD G	Hot-Dip Galvanized	150	160 mm	M8	219 mm	25 mm
ADJ150PVCPP C	Polyester	150	160 mm	M8	219 mm	25 mm
ADJ225PVCHD G	Hot-Dip Galvanized	225	251 mm	M12	346 mm	40 mm
ADJ225PVCPP C	Polyester	225	251 mm	M12	346 mm	40 mm
ADJ300PVCHD G	Hot-Dip Galvanized	300	316 mm	M12	411 mm	40 mm
ADJ300PVCPP C	Polyester	300	316 mm	M12	411 mm	40 mm

Table 2/2

Catalog Number	Thickness (T)	A	Screw Diameter (Sc)	Screw Length (L)	Static Load
ADJ040PVCHDG	3 mm	48 mm	8	25mm	1500N
ADJ040PVCPPC	3 mm	48 mm	8	25mm	1500N
ADJ050PVCHDG	3 mm	48 mm	8	25mm	1500N

Catalog Number	Thickness (T)	A	Screw Diameter (Sc)	Screw Length (L)	Static Load
ADJ050PVCPPC	3 mm	48 mm	8	25mm	1500N
ADJ065PVCHDG	3 mm	48 mm	8	25mm	1500N
ADJ065PVCPPC	3 mm	48 mm	8	25mm	1500N
ADJ080PVCHDG	3 mm	48 mm	8	25mm	1500N
ADJ100PVCHDG	3 mm	48 mm	8	25mm	1500N
ADJ100PVCPPC	3 mm	48 mm	8	25mm	1500N
ADJ150PVCHDG	3 mm	48 mm	8	25mm	1500N
ADJ150PVCPPC	3 mm	48 mm	8	25mm	1500N
ADJ225PVCHDG	5 mm	60 mm	12	50mm	6000N
ADJ225PVCPPC	5 mm	60 mm	12	50mm	6000N
ADJ300PVCHDG	5 mm	60 mm	12	50mm	7500N
ADJ300PVCPPC	5 mm	60 mm	12	50mm	7500N

DIAGRAMS

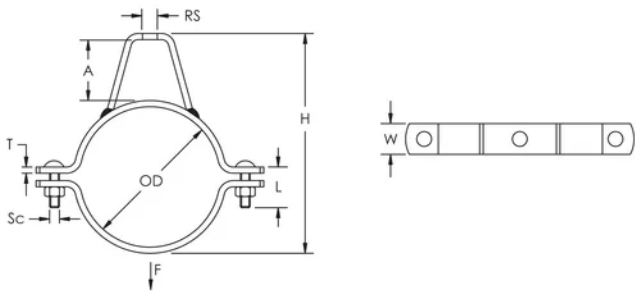

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper

installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

