

Cable Tie Holder with Flange Clip



CERTIFICATIONS



FEATURES

Used to support cables from beam flanges

Requires only a hammer to install

SPECIFICATIONS

Table 1/2


Catalog Number	Article Number	Material	Finish	Flange Thickness (FT)	A	B
4H24CTS1	160500	Stainless Steel 301 (EN 1.4310)		3 - 8 mm	9 mm	2 mm
4H58CTS1	170430	Stainless Steel 301 (EN 1.4310)		8 - 14 mm	9 mm	2 mm
4H24CT	178520	Spring Steel	nVent CADDY Armour	3 - 8 mm	9 mm	2 mm
2H4CT	178510	Spring Steel	nVent CADDY Armour	2 - 3 mm	9 mm	2 mm

CatalogNumber	Article Number	Material	Finish	Flange Thickness (FT)	A	B
4H912CTS1	170700	Stainless Steel 301 (EN 1.4310)		14 - 20 mm	9 mm	2 mm
4H912CT	178540	Spring Steel	nVent CADDY Armour	14 - 20 mm	9 mm	2 mm
4H58CT	178530	Spring Steel	nVent CADDY Armour	8 - 14 mm	9 mm	2 mm

Table 2/2

Catalog Number	Article Number	Static Load	Certifications
4H24CTS1	160500	150N	
4H58CTS1	170430	150N	
4H24CT	178520	150N	ITB
2H4CT	178510	150N	ITB
4H912CTS1	170700	150N	
4H912CT	178540	150N	ITB
4H58CT	178530	150N	ITB

DIAGRAMS

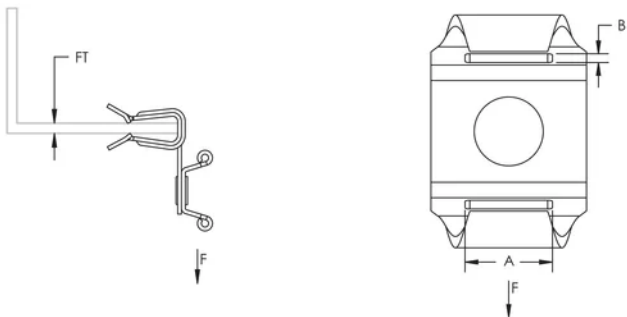

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

