

CTC Twist Clamp for Steel Pipe



FEATURES

Attaches to horizontal structural member for perpendicular pipe services

Fixes fire pipe directly to structural member

SPECIFICATIONS

Finish: Pregalvanized

Material: Steel

Table 1/2


Catalog Number	NB/DN	Outer Diameter (OD)	Hole Size (HS)	Height (H)	Width (W)	Thickness (T)
CTC32	32	42.3 mm	8 mm	94 mm	25 mm	1.5 mm
CTC40	40	48.3 mm	8 mm	100 mm	25 mm	1.5 mm
CTC50	50	60.3 mm	8 mm	120 mm	25 mm	1.5 mm
CTC25	25	33.7 mm	8 mm	85 mm	25 mm	1.5 mm
CTC65	65	76.1 mm	8 mm	138 mm	30 mm	2 mm

Table 2/2

Catalog Number	Static Load
----------------	-------------

CTC32	1500N
CTC40	1500N
CTC50	1500N
CTC25	1500N
CTC65	1500N

DIAGRAMS

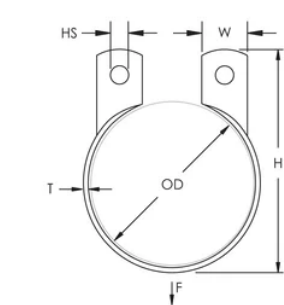

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

