

D1 Purlin Clamp



FEATURES

Straight design

Hangs threaded rod from purlins

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2


Catalog Number	Article Number	Flange Thickness (FT)	Hole Size (HS)	Height (H)	Length (L)	B
D1M8		4 mm Max	9.5 mm	36 mm	90mm	22 mm Max
D1M10	336280	4 mm Max	11 mm	36 mm	90mm	22 mm Max
D1M12		4 mm Max	13.5 mm	36 mm	90mm	22 mm Max

Table 2/2

Catalog Number	Article Number	Static Load
D1M8		1200N
D1M10	336280	600N

Catalog Number	Article Number	Static Load
D1M12		1200N

DIAGRAMS

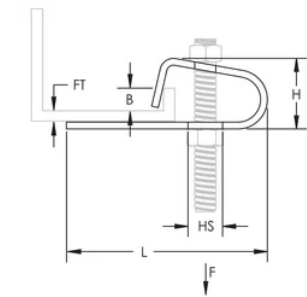

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

