

ERIC15 Saddle for Steel Pipe



CERTIFICATIONS



FEATURES

Medium duty support for steel pipe

Attaches directly to horizontal or vertical wall

Supports pipe close to wall or ceiling

SPECIFICATIONS

Finish: Hot-Dip Galvanized

Material: Steel

Table 1/2


Catalog Number	NB/DN	Outer Diameter (OD)	Hole Size (HS)	Length (L)	Width (W)	Thickness (T)
ERIC1576	65	76.1 mm	14 mm	175mm	40 mm	6 mm
ERIC15165	150	165.1 mm	14 mm	265mm	40 mm	6 mm
ERIC1589	80	88.9 mm	14 mm	190mm	40 mm	6 mm

CatalogNumber	NB/DN	Outer Diameter (OD)	Hole Size (HS)	Length (L)	Width (W)	Thickness (T)
ERIC15219	200	219 mm	14 mm	315mm	40 mm	6 mm
ERIC1560	50	60.3 mm	14 mm	160mm	40 mm	6 mm
ERIC15114	100	113.3 mm	14 mm	215mm	40 mm	6 mm

Table 2/2

Catalog Number	Static Load	Certifications
ERIC1576	3500N	AON Fire Protection, BB019, pipe hangers
ERIC15165	6000N	AON Fire Protection, BB019, pipe hangers
ERIC1589	5000N	AON Fire Protection, BB019, pipe hangers
ERIC15219	6000N	
ERIC1560	3500N	AON Fire Protection, BB019, pipe hangers
ERIC15114	6000N	

DIAGRAMS

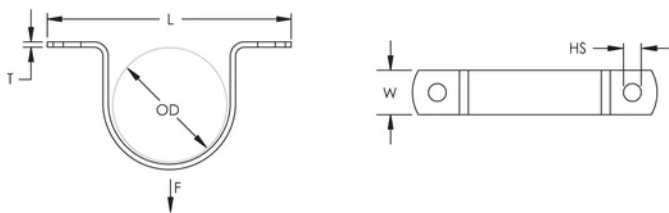

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

