

Hammer-On Flange Clip, Bottom Mount with Stud



CERTIFICATIONS



FEATURES

Can be used to support boxes, fixtures or other applications from beam flanges

Captive threaded stud minimizes the need for additional hardware

Assorted attachment points provided to reduce inventory

Requires only a hammer to install

SPECIFICATIONS

Finish: nVent CADDY Armour

Material: Spring Steel

Table 1/2


Catalog Number	Article Number	Flange Thickness (FT)	Rod Size (RS)	Screw Diameter (Sc)	Screw Length (L)	Static Load 1 (F1)
EM24SM	170530	3 - 8 mm	6	6	11mm	450N

CatalogNumber	Article Number	Flange Thickness (FT)	Rod Size (RS)	ScrewDiameter (Sc)	Screw Length (L)	Static Load 1 (F1)
EM24SM16	160440	3 - 8 mm	6	6	16mm	450N
EM58SM	172060	8 - 14 mm	6	6	11mm	450N
EM912SM	171850	14 - 20 mm	6	6	11mm	450N

Table 2/2

Catalog Number	Article Number	Static Load 2 (F2)	Static Load 3 (F3)	Certifications
EM24SM	170530	330N	110N	ITB
EM24SM16	160440	330N	110N	
EM58SM	172060	330N	110N	ITB
EM912SM	171850	330N	110N	ITB

DIAGRAMS

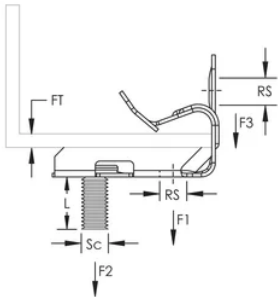

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

