

# nVent CADDY Macrofix Plus NI EZ with Easy Closure



## CERTIFICATIONS



## FEATURES

Contains easy closing mechanism

Plastic washers help prevent crushing the CPVC or plastic pipe and assure a floating fit

Flared edges and specially designed welding area help protect CPVC piping

Ideal for installations where space is limited and require services to be ran close to the attachment surface

Suitable for 3/4" - 2" (20 - 50 DN) steel sprinkler pipe

Eliminates the need to seismically brace when drops are kept within 6" (150 mm) of the attachment surface

Combo head bolt works with slotted, hex, or Phillips drivers

Conforms with Manufacturers Standardization Society (MSS) SP-58 (Type 12)

## SPECIFICATIONS

**Finish:** Electrogalvanized

**Material:** Steel

Table 1/2


Catalog Number	Article Number	NB/DN	Outer Diameter (OD)	Rod Size (RS)	Width (W)	Thickness (T)
MPZ032	595054	25	32.0 - 33.7 mm	M10	30 mm	1.5 mm
MPZ025	595053	20	25.0 - 26.9 mm	M10	30 mm	1.5 mm
MPZ040	595056	32	40.0 - 42.4 mm	M10	30 mm	1.5 mm
MPZ020	595052	15	20.0 - 21.3 mm	M10	30 mm	1.5 mm
MPZ063	595059	50	60.3 - 63 mm	M10	30 mm	2 mm
MPZ090	595062	80	88.9 - 90 mm	M10	30 mm	2 mm
MPZ050	595057	40	48.3 - 50 mm	M10	30 mm	2 mm
MPZ075	595061	65	75.0 - 76.1 mm	M10	30 mm	2 mm
MPZ110	595063	100	110.0 - 114.3 mm	M10	30 mm	2.5 mm
MPZ140	595066	125	139.7 - 141 mm	M10	30 mm	2.5 mm

Table 2/2

Catalog Number	Article Number	Static Load	Certifications
MPZ032	595054	1125N	AON Fire Protection, BB019, pipe hangers, FM Approved, Pipe Hanger Components
MPZ025	595053	1125N	FM Approved, Pipe Hanger Components, AON Fire Protection, Macrofix Plus NI EZ
MPZ040	595056	1125N	AON Fire Protection, BB019, pipe hangers, FM Approved, Pipe Hanger Components
MPZ020	595052	1125N	AON Fire Protection, BB019, pipe hangers
MPZ063	595059	1725N	FM Approved, Pipe Hanger Components, AON Fire Protection, Macrofix Plus NI EZ

Catalog Number	Article Number	Static Load	Certifications
MPZ090	595062	1725N	
MPZ050	595057	1725N	AON Fire Protection, Macrofix Plus NI EZ, FM Approved, Pipe Hanger Components
MPZ075	595061	1725N	
MPZ110	595063	2000N	
MPZ140	595066	2000N	

## DIAGRAMS

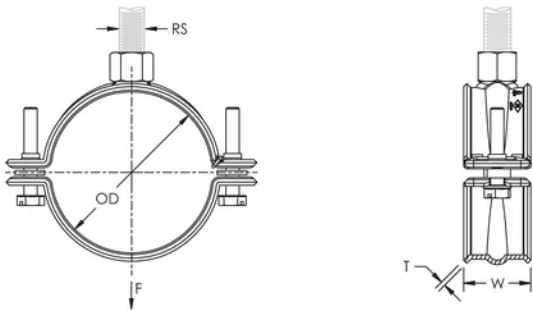

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

