

# nVent CADDY Slick Nut



## FEATURES

Provides fast universal attachment of threaded rod and hardware to standard strut profiles

## SPECIFICATIONS

**Finish:** nVent CADDY Armour

**Material:** Spring Steel

Table 1/2

| Catalog Number | Article Number | Hole Size (HS) | Hole Type | Height (H) | Torque (TQ) | Static Load 1 (F1) |
|----------------|----------------|----------------|-----------|------------|-------------|--------------------|
| SLICKM8        | 174340         | 8 mm           | Threaded  | 17 mm      | 8 N·m       | 2700N              |
| SLICKM10       | 174350         | 10 mm          | Threaded  | 17 mm      | 14 N·m Min  | 2700N              |
| SLICKM12       | 174550         | 12 mm          | Threaded  | 17 mm      | 14 N·m Min  | 2700N              |

Table 2/2

| Catalog Number | Article Number | Static Load 2 (F2) | Static Load 3 (F3) |
|----------------|----------------|--------------------|--------------------|
| SLICKM8        | 174340         | 450N               | 1100N              |
| SLICKM10       | 174350         | 450N               | 1100N              |


| Catalog Number | Article Number | Static Load 2 (F2) | Static Load 3 (F3) |
|----------------|----------------|--------------------|--------------------|
| SLICKM12       | 174550         | 450N               | 1100N              |

### ADDITIONAL PRODUCT DETAILS

Indicated loads are independent of the threaded stud or rod.

Indicated loads are applicable on 14 GA and 12 GA (2 mm and 2.5 mm) strut channels only.

### DIAGRAMS

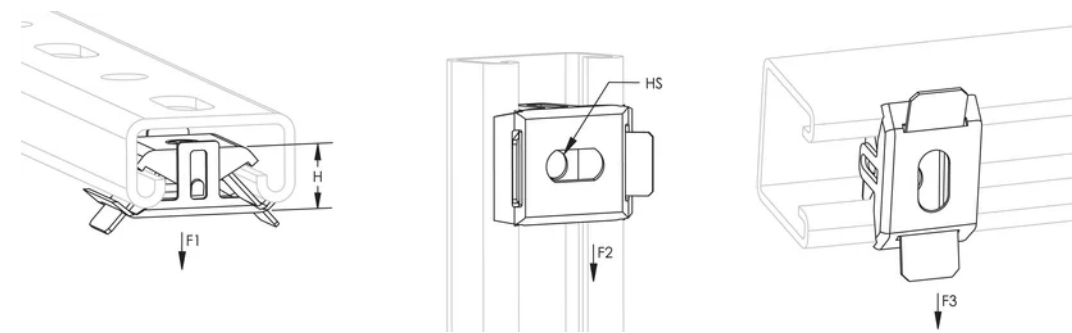

### WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221  
 Option 1 – Customer Care  
 Option 2 – Technical Support

#### Europe

Netherlands:  
 +31 800-0200135  
 France:  
 +33 800 901 793

#### Europe

Germany:  
 800 1890272  
 Other Countries:  
 +31 13 5835404

#### APAC

Shanghai:  
 + 86 21 2412 1618/19  
 Sydney:  
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

