

# PNG Loop Hanger for PVC Pipe



## FEATURES

Suspends variable pipe services

## SPECIFICATIONS

**Finish:** Polyester

**Material:** Steel


**Color:** White

Table 1/1

| Catalog Number  | Outer Diameter (OD) | Rod Size (RS) | A      | B       | C       | Static Load |
|-----------------|---------------------|---------------|--------|---------|---------|-------------|
| PNG040PVCP<br>C | 43 mm               | M10           | 78 mm  | 52 mm   | 30.5 mm | 1500N       |
| PNG050PVCP<br>C | 55 mm               | M10           | 96 mm  | 63 mm   | 34.5 mm | 1500N       |
| PNG065PVCP<br>C | 69 mm               | M10           | 111 mm | 71.5 mm | 36.5 mm | 1500N       |
| PNG080PVCP<br>C | 82 mm               | M12           | 131 mm | 82.5 mm | 41 mm   | 1500N       |

| CatalogNumber    | Outer Diameter (OD) | Rod Size (RS) | A      | B      | C       | Static Load |
|------------------|---------------------|---------------|--------|--------|---------|-------------|
| PNG100PVCPP<br>C | 110 mm              | M12           | 170 mm | 108 mm | 52.5 mm | 1500N       |
| PNG150PVCPP<br>C | 160 mm              | M12           | 230 mm | 155 mm | 74.5 mm | 1500N       |
| PNG225PVCPP<br>C | 250 mm              | M12           | 391 mm | 255 mm | 129 mm  | 6000N       |
| PNG300PVCPP<br>C | 315 mm              | M12           | 493 mm | 325 mm | 167 mm  | 7500N       |

## DIAGRAMS

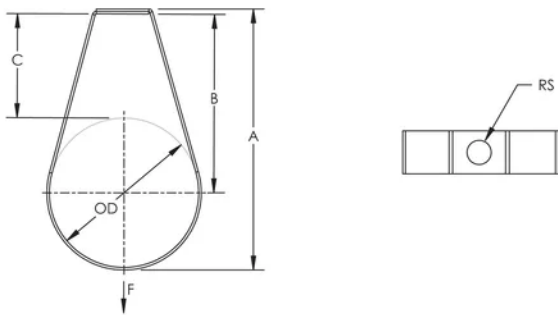

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

