

Rod Connector to Pipe Clamp



FEATURES

Hanging bracket, Clevis type

Two piece clamp extension

Fasten from horizontal to vertical hanging configurations

Use in conjunction with all channel profiles

SPECIFICATIONS


Finish: Hot-Dip Galvanized

Material: Steel

Table 1/1

Catalog Number	Hole Size 1 (HS1)	Hole Size 2 (HS2)	Height (H)	Width (W)	Thickness (T)	Static Load
ERIC8	10 mm	10 mm	100 mm	25 mm	3 mm	750N
ERIC10	12 mm	10 mm	113 mm	25 mm	5 mm	1350N
ERIC16	18 mm	14 mm	112.5 mm	50 mm	6 mm	4400N
ERIC12	14 mm	14 mm	118 mm	40 mm	6 mm	2650N

DIAGRAMS

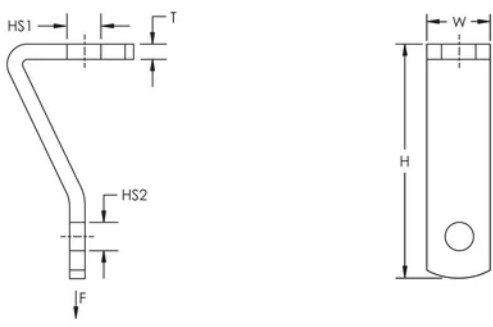

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

