

SOB Pipe Clamp for PVC Pipe



FEATURES

Stand off bracket for vertical pipe services

Attaches directly to horizontal or vertical structural member

Double bolted

SPECIFICATIONS

Finish: Polyester

Material: Steel

Color: White

Table 1/2


Catalog Number	NB/DN	Outer Diameter (OD)	A	Width (W)	Thickness (T)	Hole Size (HS)
SOB150PVCPP C	150	160 mm	220 mm	25 mm	3 mm	10 mm
SOB100PVCPP C	100	110 mm	165 mm	20 mm	3 mm	10 mm
SOB300PVCPP C	300	316 mm	435 mm	40 mm	6 mm	13.5 mm

CatalogNumber	NB/DN	Outer Diameter (OD)	A	Width (W)	Thickness (T)	Hole Size (HS)
SOB225PVCPPC C	225	251 mm	368 mm	40 mm	6 mm	13.5 mm

Table 2/2

Catalog Number	Screw Diameter (Sc)	Screw Length (L)	Static Load
SOB150PVCPPC	8	25mm	1500N
SOB100PVCPPC	8	25mm	1500N
SOB300PVCPPC	12	40mm	7500N
SOB225PVCPPC	12	40mm	6000N

DIAGRAMS

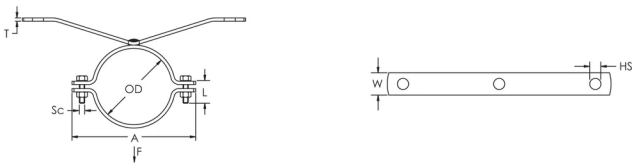

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

