

Strut Nut without Spring



FEATURES

Used to create metal frames with nVent CADDY Eristrut channels

SPECIFICATIONS



Static Load Safety Factor: 3:1

Table 1/1

Catalog Number	Article Number	Material	Finish	Rod Size (RS)	Thickness (T)	Torque (TQ)
NUTM8HD	315010	Steel	Hot-Dip Galvanized	8	6 mm	28 N·m
NUTM6HD	315000	Steel	Hot-Dip Galvanized	6	6 mm	12 N·m
NUTM12HD	315030	Steel	Hot-Dip Galvanized	12	8 mm	55 N·m
NUTM10HD	315020	Steel	Hot-Dip Galvanized	10	8 mm	55 N·m
NUTM10S6	315160	Stainless Steel 316 (EN 1.4401)		10	8 mm	55 N·m
NUTM12S6	315170	Stainless Steel 316 (EN 1.4401)		12	8 mm	55 N·m

Pull-Out Strength				
Part Number	Channel Type	Channel Thickness		
		2,5 mm	2 mm	1,5 mm
NUTM6xx	A, C	2000 N	2000 N	2000 N
	D, E	2000 N	-	-
NUTM8xx	A, C	3330 N	3330 N	3330 N
	D, E	3330 N	-	-
NUTM10xx	A, C	4890 N	4440 N	4440 N
	D, E	4890 N	-	-
NUTM12xx	A, C	4890 N	4660 N	4440 N
	D, E	3670 N	-	-
NUTM12Txx	A	5670 N	5050 N	4440 N
	D, E	4250 N	-	-
NUTM16xx	A	5670 N	4660 N	4440 N
	D, E	4250 N	-	-

DIAGRAMS

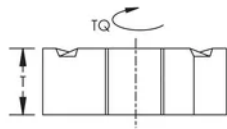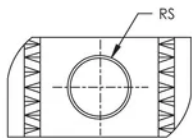

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

