

Vertical Pipe Clamp for Fiber Reinforced Concrete Pipe



FEATURES

Medium Duty

Adjustable suspension of horizontal and vertical pipe services

Double bolted

SPECIFICATIONS

Finish: Hot-Dip Galvanized

Material: Steel

Table 1/2


Catalog Number	NB/DN	Outer Diameter (OD)	A	Screw Diameter (Sc)	Screw Length (L)	Thickness (T)
TPC300FRCHD G	300	358 mm	470 mm	12	40mm	6 mm
TPC225FRCHD G	225	277 mm	388 mm	12	40mm	6 mm
TPC375FRCHD G	375	438 mm	565 mm	16	50mm	8 mm

CatalogNumber	NB/DN	Outer Diameter (OD)	A	ScrewDiameter (Sc)	Screw Length (L)	Thickness (T)
TPC450FRCHD G	450	527 mm	655 mm	16	50mm	8 mm

Table 2/2

Catalog Number	Static Load
TPC300FRCHDG	7500N
TPC225FRCHDG	6000N
TPC375FRCHDG	9000N
TPC450FRCHDG	10000N

DIAGRAMS

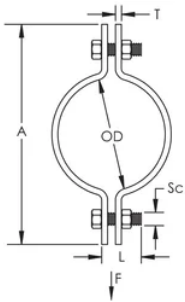

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

