

VMP Vertical Mounting Plate



CERTIFICATIONS



FEATURES

Supports pipe from wood, concrete or steel structures

Installs on vertical mounting surface

Pre-threaded captive nut allows for easy adjustment

Eliminates the need for additional hardware

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel


Table 1/2

Catalog Number	Rod Size (RS)	Height (H)	Width (W)	Thickness (T)	Hole Size (HS)	A
VMP8	8	100 mm	25 mm	3 mm	6.5 mm	6.5 mm
VMP10	10	100 mm	25 mm	3 mm	6.5 mm	6.5 mm

CatalogNumber	Rod Size (RS)	Height (H)	Width (W)	Thickness (T)	Hole Size (HS)	A
VMP12	12	100 mm	25 mm	3 mm	6.5 mm	6.5 mm

Table 2/2			
Catalog Number	B	Static Load	Certifications
VMP8	10 mm	2500N	
VMP10	10 mm	3000N	
VMP12	10 mm	4000N	AON Fire Protection, BB019, pipe hangers

DIAGRAMS

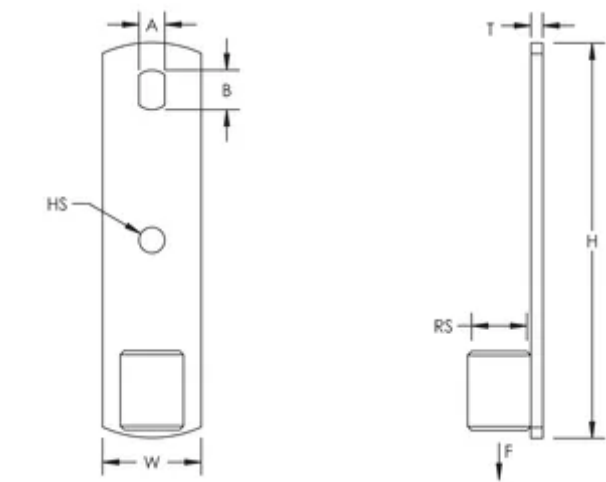

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

