

WBT Performance Cable Tray C Bracket



Engineered for efficiency and adaptability, the nVent CADDY WBT Performance Cable Tray C Bracket is a fast and simple component of modern cable management systems.

Designed to streamline installation processes, this bracket excels in both hard-ceiling and two-tier wall mounting scenarios, offering contractors a reliable and time-saving solution for complex environments

The C Bracket ensures that high-performance, low-voltage and data cables are securely supported with minimal effort. Simply pair with the nVent CADDY WBT Performance Cable Tray Washer Support or nVent CADDY WBT Performance Cable Tray Ground Splice and quickly fasten it to the wire basket tray to create a robust framework for layered tray runs. This combination not only enhances structural integrity but also provides the flexibility needed for multi-tiered installations, accommodating evolving infrastructure demands without compromising safety or performance

FEATURES

Easy-to-use quick connect feature

Designed to be used with the nVent CADDY WBT Performance Cable Tray Washer Support and nVent CADDY WBT Performance Cable Tray Ground Splice

Side load access for cable installation

Ideal for ceiling, wall and channel installations

Side load access for simple cable installation

SPECIFICATIONS

Finish: Electrogalvanized

Material: Steel

Table 1/2

Catalog Number	Color	Height (H)	Width (W)	Length (L)	Length 1 (L1)	Hole Size (HS)
WBTCBRKT12		200.03 mm	41.4 mm	350.52mm	139.7 mm	7.137 mm


CatalogNumber	Color	Height (H)	Width (W)	Length (L)	Length 1 (L1)	Hole Size (HS)
WBTCBRKT12B A	Black	200.03 mm	41.4 mm	350.52mm	139.7 mm	7.137 mm
WBTCBRKT12 WH	White	200.03 mm	41.4 mm	350.52mm	139.7 mm	7.137 mm
WBTCBRKT18		200.03 mm	41.4 mm	499.11mm	139.7 mm	7.137 mm
WBTCBRKT18B A	Black	200.03 mm	41.4 mm	499.11mm	139.7 mm	7.137 mm
WBTCBRKT18 WH	White	200.03 mm	41.4 mm	499.11mm	139.7 mm	7.137 mm
WBTCBRKT4		200.03 mm	41.4 mm	151.917mm	139.7 mm	7.137 mm
WBTCBRKT4BA	Black	200.03 mm	41.4 mm	151.917mm	139.7 mm	7.137 mm
WBTCBRKT6		200.03 mm	41.4 mm	201.93mm	139.7 mm	7.137 mm
WBTCBRKT6BA	Black	200.03 mm	41.4 mm	201.93mm	139.7 mm	7.137 mm
WBTCBRKT8		200.03 mm	41.4 mm	251.46mm	139.7 mm	7.137 mm
WBTCBRKT8BA	Black	200.03 mm	41.4 mm	251.46mm	139.7 mm	7.137 mm

Table 2/2

Catalog Number	Unit Weight
WBTCBRKT12	1.025 kg
WBTCBRKT12BA	1.025 kg
WBTCBRKT12WH	1.025 kg
WBTCBRKT18	1.27 kg
WBTCBRKT18BA	1.27 kg

Catalog Number	Unit Weight
WBTCBRKT18WH	1.27 kg
WBTCBRKT4	0.708 kg
WBTCBRKT4BA	0.708 kg
WBTCBRKT6	0.789 kg
WBTCBRKT6BA	0.789 kg
WBTCBRKT8	0.866 kg
WBTCBRKT8BA	0.866 kg

DIAGRAMS

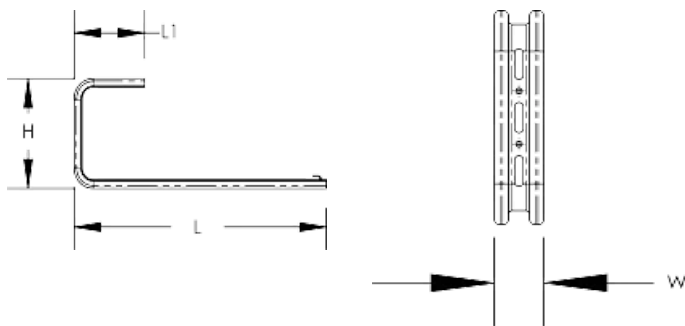

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

