

SB/SBL Hollow Core Rail Drill Bit



FEATURES

Designed for high-speed drilling applications

Withstands approximately 40 uses

Can be reground for further use

Specifically developed for rail steel

3/4" (19 mm) Weldon shank

Allows for short drill times

High durability provides extended lifetime

SPECIFICATIONS

Material: High-Speed Steel


Finish: TIALN Coating

Table 1/1

Catalog Number	Article Number	Drill Bit Diameter (Ø)	Length (L)
DHC18	716492	18 mm	63mm
DHC19	716493	19 mm	63mm
DHC23	716494	23 mm	63mm
DHC25	716495	25 mm	63mm

Catalog Number	Article Number	Drill Bit Diameter (Ø)	Length (L)
DHC27	716496	27 mm	63mm
DHC35	716497	35 mm	63mm
DHC36	716498	36 mm	63mm
DSB1670	715251	16 mm	70mm
DSB1770	715252	17 mm	70mm
DSB2270	715255	22 mm	70mm
DSBL1690	716301	16 mm	90mm

DIAGRAMS

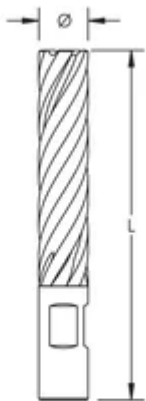

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE