


# Plug-In Unit Kit for PMC, Chromated, Shielded (Textile) With Handle

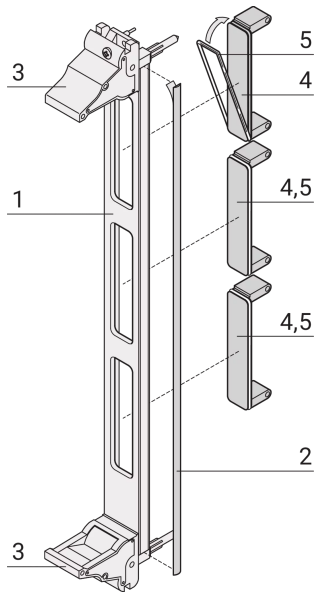

U-shaped front panel with cutout for PMC. Shieldable for textile EMC gasket.

## FEATURES

In accordance with IEEE P1386, PCI Mezzanine Card

For single 69.0 x 76.5 mm or double 139.0 x 76.5 mm modules

For standard defined I/O mezzanine modules which connect to carrier cards

PMC = PCI Mezzanine Card

FPGA = Field Programmable Gate Array

U-profile front panel 3 U, 4 HP, with textile gasketing

EMC shielding for front panel and coverings for front panel cutouts

## SPECIFICATIONS

|                       |                               |
|-----------------------|-------------------------------|
| <b>Rack Width:</b>    | 4HP                           |
| <b>Material:</b>      | Aluminum                      |
| <b>Product Type:</b>  | Front Panel                   |
| <b>Type:</b>          | Front Panel with Handle (PIU) |
| <b>EMC Shielding:</b> | Yes                           |

Table 1/2

| Catalog Number | Rack Height | Package Quantity | Handle Type | Mounting       | EMC Gasket Type | Front Finish |
|----------------|-------------|------------------|-------------|----------------|-----------------|--------------|
| 20836-460      | 3U          | 1                | IEL         | Screw-on Front | Textile         | Anodized     |
| 20836-461      | 6U          | 1                | IEL         | Screw-on Front | Textile         | Anodized     |

Table 2/2

| Catalog Number | Rear Finish | Complies With             | Finish               | Quick Ship |
|----------------|-------------|---------------------------|----------------------|------------|
| 20836-460      | Conductive  | PMC Mezzanine, IEEE P1386 | Anodized, Passivated | No         |
| 20836-461      | Conductive  | PMC Mezzanine, IEEE P1386 | Anodized, Passivated | No         |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**