

EER-Ti/T Trapezoidal Deck Threaded Rod Hanger



CERTIFICATIONS



FEATURES

Supports threaded rod

Thread impression for simple installation

SPECIFICATIONS

Finish: nVent CADDY Armour

Material: Spring Steel

Table 1/2

Catalog Number	Article Number	Hole Size (HS)	Hole Type	Flange Thickness (FT)	Drill Bit Diameter	Static Load 1 (F1)
EERTIM6	173120	6 mm	Threaded	0.8 - 3 mm	7mm	450N
EERTIM10	173140	10 mm	Threaded	0.8 - 3 mm	7mm	450N


CatalogNumber	Article Number	Hole Size (HS)	Hole Type	Flange Thickness (FT)	Drill Bit Diameter	Static Load 1 (F1)
EERTIM8	173130	8 mm	Threaded	0.8 - 3 mm	7mm	450N

Table 2/2			
Catalog Number	Article Number	Static Load 2 (F2)	Certifications
EERTIM6	173120	900N	
EERTIM10	173140	900N	ITB
EERTIM8	173130	900N	ITB

ADDITIONAL PRODUCT DETAILS

Static Load 1 represents 0.8 - 2.0 mm flange thickness. Static Load 2 represents 2.0 - 3.0 mm flange thickness.

DIAGRAMS

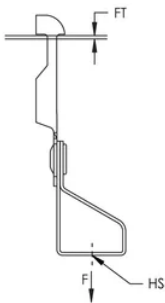

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

CADDY

ERICO

HOFFMAN

ILSCO

SCHROFF

TRACHTE

