

# KP T-Bolt for C-Channel E0/E0L/E1



## FEATURES

For use with C-Profiles

Pre-mounted with large washer and nut

## SPECIFICATIONS

**Channel Type:** E0;E0L;E1  
**Finish:** Electrogalvanized  
**Material:** Steel

Table 1/1


Catalog Number	Article Number	Screw Diameter (Sc)	Screw Length (L)	A	B
KP2708020	590074	8	20mm	25 mm	14 mm
KP2708030	590076	8	30mm	25 mm	14 mm
KP2708040	590077	8	40mm	25 mm	14 mm
KP2708080	590082	8	80mm	25 mm	14 mm
KP2710030	590087	10	30mm	25 mm	14 mm

ADDITIONAL PRODUCT DETAILS

Sliding force F2 is limited to 600 N for all types of Nuts and T-Bolts for C-channel System.

Nuts and T-Bolts for C-channel System	
C-Channel Type	Pullout Force F1
E0	1300 N
E0L	800 N
E1	1900 N

DIAGRAMS

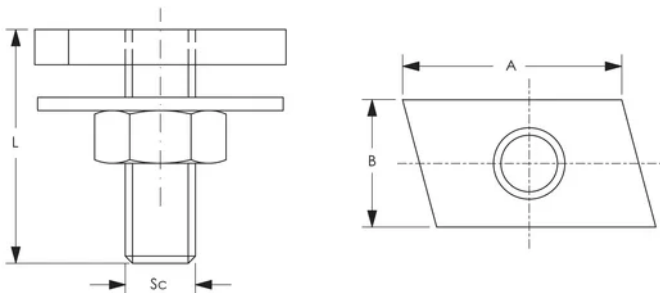

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE

