


## Drain-Breather, DPE

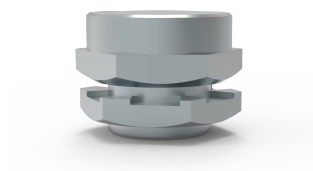

This stainless steel 316L element combine drainage and breathing and it is especially for use in potentially explosive atmosphere 'EX e'.

### FEATURES

Description: Combination of drainage and breathing elements especially for use in potentially explosive atmosphere 'EX e'.

Protection degree: IP 66.

Temperature range: -30°C to 100°C.

Pack quantity: 1 piece.

SPECIFICATIONS

| Table 1/1      |                             |                             |                      |         |            |
|----------------|-----------------------------|-----------------------------|----------------------|---------|------------|
| Catalog Number | Enclosure Material          | Product Family              | Material             | Finish  | Quick Ship |
| DPE3004S3      | Mild Steel, Stainless Steel | Free-Standing, Wall Mounted | Stainless Steel 316L | Brushed | No         |

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE