

# Bolt Close Conduit/Pipe Clamp



## CERTIFICATIONS



## FEATURES

Retained bolt and built-in nut means there are less parts to handle or drop

Combo head bolt works with slotted, hex, #3 phillips or #2 robertson drivers

## SPECIFICATIONS

Table 1/2

| Catalog Number | Article Number | Material                        | Finish            | Nut Type     | Outer Diameter (OD) | Hole Size (HS) |
|----------------|----------------|---------------------------------|-------------------|--------------|---------------------|----------------|
| CD2.5BSS       |                | Stainless Steel 304 (EN 1.4301) |                   | Hex Nut      | 31 - 38 mm          | 6.75 mm        |
| CD2BSS         |                | Stainless Steel 304 (EN 1.4301) |                   | Hex Nut      | 25 - 33 mm          | 6.75 mm        |
| CD3BSS         |                | Stainless Steel 304 (EN 1.4301) |                   | Hex Nut      | 36 - 43 mm          | 6.75 mm        |
| CD0B           | 181140         | Steel                           | Electrogalvanized | Built-In Nut | 17 - 22 mm          | 7.14 mm        |

| CatalogNumber | Article Number | Material                        | Finish            | Nut Type     | Outer Diameter (OD) | Hole Size (HS) |
|---------------|----------------|---------------------------------|-------------------|--------------|---------------------|----------------|
| CD0BSS        |                | Stainless Steel 304 (EN 1.4301) |                   | Hex Nut      | 17 - 22 mm          | 7.14 mm        |
| CD1B          | 181190         | Steel                           | Electrogalvanized | Built-In Nut | 19 - 25 mm          | 7.14 mm        |
| CD1BSS        |                | Stainless Steel 304 (EN 1.4301) |                   | Hex Nut      | 19 - 25 mm          | 7.14 mm        |
| CD2.5B        | 181370         | Steel                           | Electrogalvanized | Built-In Nut | 31 - 38 mm          | 7.14 mm        |
| CD2B          | 181150         | Steel                           | Electrogalvanized | Built-In Nut | 25 - 33 mm          | 7.14 mm        |
| CD3B          | 181380         | Steel                           | Electrogalvanized | Built-In Nut | 36 - 43 mm          | 7.14 mm        |
| CD4B          | 181390         | Steel                           | Electrogalvanized | Built-In Nut | 45 - 48 mm          | 7.14 mm        |
| CD4BSS        |                | Stainless Steel 304 (EN 1.4301) |                   | Hex Nut      | 45 - 48 mm          | 7.14 mm        |
| CD5B          | 181470         | Steel                           | Electrogalvanized | Built-In Nut | 49 - 73 mm          | 7.14 mm        |
| CD5BSS        |                | Stainless Steel 304 (EN 1.4301) |                   | Hex Nut      | 49 - 73 mm          | 7.14 mm        |
| CD6B          | 181480         | Steel                           | Electrogalvanized | Hex Nut      | 66 - 76 mm          | 7.9 mm         |
| CD7B          | 181490         | Steel                           | Electrogalvanized | Hex Nut      | 80 - 90 mm          | 7.9 mm         |
| CD8B          | 181500         | Steel                           | Electrogalvanized | Hex Nut      | 95 - 105 mm         | 7.9 mm         |
| CD9B          | 181540         | Steel                           | Electrogalvanized | Hex Nut      | 108 - 115 mm        | 7.9 mm         |
| CD6BSS        |                | Stainless Steel 304 (EN 1.4301) |                   | Hex Nut      | 66 - 76 mm          | 8.33 mm        |
| CD7BSS        |                | Stainless Steel 304 (EN 1.4301) |                   | Hex Nut      | 80 - 90 mm          | 8.33 mm        |


| CatalogNumber | Article Number | Material                        | Finish            | Nut Type     | Outer Diameter (OD) | Hole Size (HS) |
|---------------|----------------|---------------------------------|-------------------|--------------|---------------------|----------------|
| CD8BSS        |                | Stainless Steel 304 (EN 1.4301) |                   | Hex Nut      | 95 - 105 mm         | 8.33 mm        |
| CD9BSS        |                | Stainless Steel 304 (EN 1.4301) |                   | Hex Nut      | 108 - 115 mm        | 8.33 mm        |
| CD1B37        |                | Steel                           | Electrogalvanized | Built-In Nut | 19 - 25 mm          | 10.32 mm       |
| CD2B37        |                | Steel                           | Electrogalvanized | Built-In Nut | 25 - 33 mm          | 10.32 mm       |

Table 2/2

| Catalog Number | Article Number | Static Load 1 (F1) | Static Load 2 (F2) | Certifications |
|----------------|----------------|--------------------|--------------------|----------------|
| CD2.5BSS       |                | 880N               | 220N               | cUL, UL        |
| CD2BSS         |                | 880N               | 220N               |                |
| CD3BSS         |                | 880N               | 220N               | cUL, UL        |
| CD0B           | 181140         | 880N               | 220N               | UL, cUL        |
| CD0BSS         |                | 880N               | 220N               | UL, cUL        |
| CD1B           | 181190         | 880N               | 220N               | UL, cUL, ITB   |
| CD1BSS         |                | 880N               | 220N               | cUL, UL        |
| CD2.5B         | 181370         | 880N               | 220N               | UL, cUL        |
| CD2B           | 181150         | 880N               | 220N               | UL, cUL        |
| CD3B           | 181380         | 880N               | 220N               | UL, ITB, cUL   |
| CD4B           | 181390         | 880N               | 220N               | UL, cUL, ITB   |
| CD4BSS         |                | 880N               | 220N               | cUL, UL        |

| Catalog Number | Article Number | Static Load 1 (F1) | Static Load 2 (F2) | Certifications |
|----------------|----------------|--------------------|--------------------|----------------|
| CD5B           | 181470         | 880N               | 220N               | ITB, UL, cUL   |
| CD5BSS         |                | 1550N              | 220N               | UL, cUL        |
| CD6B           | 181480         | 1550N              | 220N               |                |
| CD7B           | 181490         | 1550N              | 220N               |                |
| CD8B           | 181500         | 1550N              | 220N               |                |
| CD9B           | 181540         | 1550N              | 220N               |                |
| CD6BSS         |                | 1550N              | 220N               |                |
| CD7BSS         |                | 1550N              | 220N               |                |
| CD8BSS         |                | 1550N              | 220N               |                |
| CD9BSS         |                | 1550N              | 220N               |                |
| CD1B37         |                | 880N               | 220N               |                |
| CD2B37         |                | 880N               | 220N               |                |

## DIAGRAMS

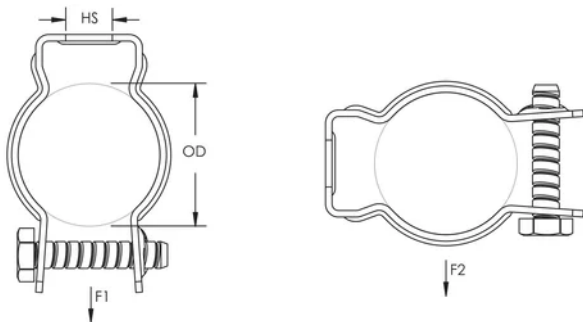

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause

product malfunction, property damage, serious bodily injury and death and/or void your warranty.

**North America**

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

**Europe**

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

**Europe**

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

**APAC**

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**

