

# EM-P Conduit to Flange Clip



## CERTIFICATIONS



## FEATURES

Requires only a hammer to install

Available for EMT, rigid, IMT and aluminum conduit

Will pivot thru 360°

## SPECIFICATIONS

**Finish:** nVent CADDY Armour


**Material:** Spring Steel

Table 1/1

Catalog Number	Article Number	Outer Diameter (OD)	Flange Thickness (FT)	Ultimate Static Load (F)	Certifications
12P24	175110	22 - 30 mm	3 - 8 mm	110N	
16P24	175140	30 - 35 mm	3 - 8 mm	110N	
8P24	172150	18 - 22 mm	3 - 8 mm	110N	ITB

Catalog Number	Article Number	Outer Diameter (OD)	Flange Thickness (FT)	Ultimate Static Load (F)	Certifications
12P58	175120	22 - 30 mm	8 - 14 mm	110N	
16P58	175150	30 - 35 mm	8 - 14 mm	110N	
8P58	172160	18 - 22 mm	8 - 14 mm	110N	ITB
8P912	175100	18 - 22 mm	14 - 20 mm	110N	ITB
12P912	175130	22 - 30 mm	14 - 20 mm	110N	
16P912	175160	30 - 35 mm	14 - 20 mm	110N	

## DIAGRAMS

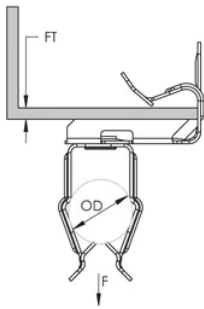

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

#### North America

+1.800.753.9221

Option 1 – Customer Care

Option 2 – Technical

Support

#### Europe

Netherlands:

+31 800-0200135

France:

+33 800 901 793

#### Europe

Germany:

800 1890272

Other Countries:

+31 13 5835404

#### APAC

Shanghai:

+ 86 21 2412 1618/19

Sydney:

+61 2 9751 8500



Our powerful portfolio of brands:

**CADDY**

**ERICO**

**HOFFMAN**

**ILSCO**

**SCHROFF**

**TRACHTE**

