

nVent CADDY Speed Link Y-Toggle with Eyelet Extension



CERTIFICATIONS



FEATURES

Attaches to clearance holes in a variety of structures or hanging devices

Ideal for supporting lighting fixtures

Y-design provides improved stability

SPECIFICATIONS

Static Load Safety Factor: 5:1
Finish: Electrogalvanized
Material: Steel

Table 1/2

Catalog Number	Article Number	Wire Rope Diameter	Wire Rope "Y" Length (YL)	A	B	Static Load
SLD15Y200	195999	1.5 mm	0.2m	39 mm	5 mm	195N

CatalogNumber	Article Number	Wire Rope Diameter	Wire Rope "Y" Length (YL)	A	B	Static Load
SLD15Y300	196000	1.5 mm	0.3m	39 mm	5 mm	195N
SLD15Y500	195960	1.5 mm	0.5m	39 mm	5 mm	195N
SLD2Y300	196036	2 mm	0.3m	42 mm	8 mm	440N
SLD2Y500	176870	2 mm	0.5m	42 mm	8 mm	440N


Table 2/2

Catalog Number	Article Number	Certifications
SLD15Y200	195999	cUL, UL
SLD15Y300	196000	UL, cUL
SLD15Y500	195960	UL, cUL, ITB
SLD2Y300	196036	UL, cUL
SLD2Y500	176870	cUL, ITB, UL

ADDITIONAL PRODUCT DETAILS

nVent CADDY Speed Link locking device not included.

DIAGRAMS

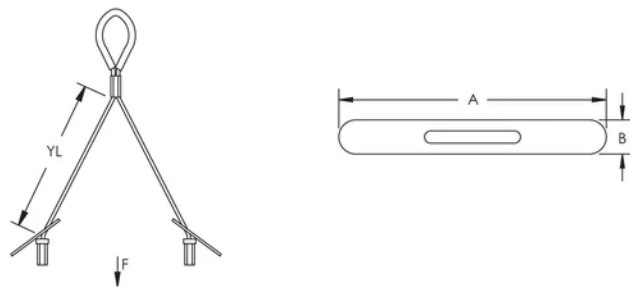

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
Option 1 – Customer Care
Option 2 – Technical
Support

Europe

Netherlands:
+31 800-0200135
France:
+33 800 901 793

Europe

Germany:
800 1890272
Other Countries:
+31 13 5835404

APAC

Shanghai:
+ 86 21 2412 1618/19
Sydney:
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

