

SCH1 Single Piece Strut Clamp for Conduit



CERTIFICATIONS



FEATURES

One-piece conduit clamp

No screws or bolts to drop

Requires only a screwdriver or nutdriver for installation

Fits into open side of strut channel

SPECIFICATIONS

Finish: Electrogalvanized


Material: Steel

Table 1/1

Catalog Number	Outer Diameter (OD)	Static Load
SCH8	8.6 - 18 mm	880N
SCH12	14.5 - 23.4 mm	880N

Catalog Number	Outer Diameter (OD)	Static Load
SCH16	18.3 - 29.5 mm	880N
SCH20	25.4 - 38.4 mm	880N

DIAGRAMS

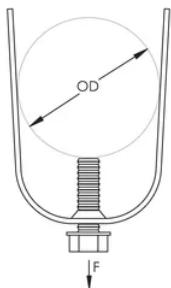

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221
 Option 1 – Customer Care
 Option 2 – Technical Support

Europe

Netherlands:
 +31 800-0200135
 France:
 +33 800 901 793

Europe

Germany:
 800 1890272
 Other Countries:
 +31 13 5835404

APAC

Shanghai:
 + 86 21 2412 1618/19
 Sydney:
 +61 2 9751 8500



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE

