

# 2 Hole Lug, GL Style



## FEATURES

Provides an efficient bolting surface for grounding and power applications

Electrolytic grade copper

For use with nVent ERICO Cadweld type GL connections only

## SPECIFICATIONS

**Material:** Copper

**Finish:** Tinned

Table 1/2

Catalog Number	Article Number	Type	Height (H)	Length (L)	Width (W)	Thickness (T)
B122CE	183660	NEMA®	11.18 mm	81.03mm	25.4 mm	3.18 mm
B123CE03		Non-NEMA®	11.18 mm	62.74mm	25.4 mm	3.18 mm
B122DE		NEMA®	11.18 mm	82.55mm	25.4 mm	4.76 mm
B122DE002		NEMA®	11.18 mm	62.74mm	25.4 mm	4.76 mm
B122EE		NEMA®	11.18 mm	82.55mm	25.4 mm	6.35 mm

CatalogNumber	Article Number	Type	Height (H)	Length (L)	Width (W)	Thickness (T)
B122EG		NEMA®	11.18 mm	82.55mm	38.1 mm	6.35 mm
B122EG002		Non-NEMA®	11.18 mm	82.55mm	82.55 mm	6.35 mm
B123EG03		Non-NEMA®	11.18 mm	82.55mm	38.1 mm	6.35 mm


Table 2/2

Catalog Number	Article Number	A	B	Hole Size (HS)	Angle (a)	Equivalent Conductor Size
B122CE	183660	15.9 mm	44.45 mm	14.29 mm	90 °	80.63mm <sup>2</sup>
B123CE03		15.9 mm	44.45 mm	11.11 mm	90 °	80.63mm <sup>2</sup>
B122DE		15.9 mm	44.45 mm	14.29 mm	90 °	120.94mm <sup>2</sup>
B122DE002		15.9 mm	44.45 mm	11.11 mm	90 °	120.94mm <sup>2</sup>
B122EE		15.9 mm	44.45 mm	14.29 mm	90 °	161.26mm <sup>2</sup>
B122EG		15.9 mm	44.45 mm	14.29 mm	90 °	241.89mm <sup>2</sup>
B122EG002		15.9 mm	44.45 mm	17.46 mm	45 °	524.09mm <sup>2</sup>
B123EG03		15.9 mm	44.45 mm	11.11 mm	90 °	241.89mm <sup>2</sup>

## ADDITIONAL PRODUCT DETAILS

For sizes not listed, contact us.

DIAGRAMS

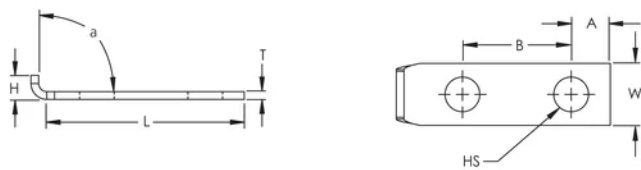

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

North America

+1.800.753.9221  
Option 1 – Customer Care  
Option 2 – Technical  
Support

Europe

Netherlands:  
+31 800-0200135  
France:  
+33 800 901 793

Europe

Germany:  
800 1890272  
Other Countries:  
+31 13 5835404

APAC

Shanghai:  
+ 86 21 2412 1618/19  
Sydney:  
+61 2 9751 8500



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE