


# Cable Entry Gland Plate Grommet Small, CCFGSX

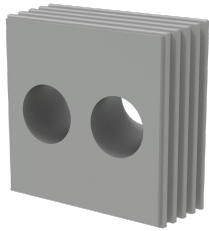

CCFGS cable glands are used with CCFI, CCFO and CCFR cable entry systems.

## FEATURES

---

Wave-cut profile supports easy installs ensuring a perfect fit around cables.

The conical shape of the grommets allows them to be easily pressed in, provides static strain relief in accordance with DIN EN 6244

For assembly, they are pressed from the inside out into the openings of the assembled inlays

The grommets are available in different sizes to match the diameter of the cable

## SPECIFICATIONS

**Color:** Gray

**Finish:** Smooth Matte

Table 1/1

| Catalog Number | Article Number | Height | Width | Depth  | Material                | Operating Temperature |
|----------------|----------------|--------|-------|--------|-------------------------|-----------------------|
| CCFGSX25       | 59517          | 20.3mm | 20mm  | 17.7mm | Thermoplastic Elastomer | -40 to 90°C           |
| CCFGSX26       | 59518          | 20.3mm | 20mm  | 17.7mm | Thermoplastic Elastomer | -40 to 90°C           |
| CCFGSX265      | 59524          | 20.3mm | 20mm  | 17.7mm | Thermoplastic Elastomer | -40 to 90°C           |
| CCFGSX27       | 59514          | 20.3mm | 20mm  | 17.7mm | Thermoplastic Elastomer | -40 to 90°C           |
| CCFGSX28       | 59515          | 20.3mm | 20mm  | 17.7mm | Thermoplastic Elastomer | -40 to 90°C           |
| CCFGSX36       | 59513          | 20.3mm | 20mm  | 17.7mm | Thermoplastic Elastomer | -40 to 90°C           |
| CCFGSX43       | 59519          | 20.3mm | 20mm  | 17.7mm | Thermoplastic Elastomer | -40 to 90°C           |
| CCFGSX44       | 59522          | 20.3mm | 20mm  | 17.7mm | Thermoplastic Elastomer | -40 to 90°C           |
| CCFGSX445      | 59523          | 20.3mm | 20mm  | 17.7mm | Thermoplastic Elastomer | -40 to 90°C           |
| CCFGSX45       | 59512          | 20.3mm | 20mm  | 17.7mm | Thermoplastic Elastomer | -40 to 90°C           |
| CCFGSX46       | 59516          | 20.3mm | 20mm  | 17.7mm | Thermoplastic Elastomer | -40 to 90°C           |

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

**CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE**