


Fusion G7 Half-Height Back Panel

Galvanized steel half-height back panels.

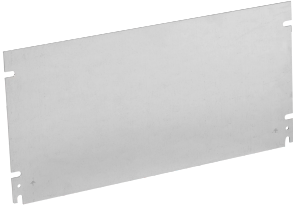

FEATURES

Galvanized steel half-height back panel

SPECIFICATIONS

Table 1/1						
Catalog Number	Article Number	Height	Width	Material	Finish	Thickness
G1000P800H	19052	470mm	754mm	Mild Steel	Galvanized	2mm

ADDITIONAL PRODUCT DETAILS

M8 panel mounting nuts provided with 50-mm front-to-back side mount accessory rails and side-mount accessory rail brackets.

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE