


ProLine Sloped-Front HMI Enclosure Rear Door

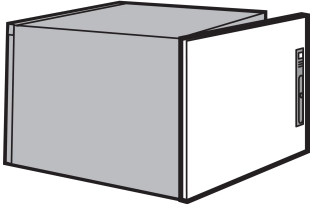

Rear doors are side-hinged. The hinges are hidden and provide 130-degree door swing. Optional ProLine 180-Degree Hinge Kit is available. Doors can be hinged from left or right. Door includes two-point latching with a flush slotted quarter-turn insert. Standard ProLine handle and insert options are available for retrofit. Use ProLine Frame Shelf or ProLine Grid Straps to support the operator interface. Ground stud and mounting hardware are included. Seamless foam-in-place gasket assures a watertight and dust-tight seal.

FEATURES

Side hinged doors with 130-degree swing

Seamless foam in place gasket

SPECIFICATIONS

Color: Light Gray
Material: Mild Steel
Finish: Powder Coated
Color Code: RAL 7035

Table 1/1

Catalog Number	Article Number	Height	Width	Depth	Thickness	Door Size
PDS46R	36849	400mm	600mm	565mm	1.52mm	405 x 592mm
PDS56R	36859	500mm	600mm	565mm	1.52mm	506 x 592mm
PDS5A6R	36869	500mm	600mm	565mm	1.52mm	679 x 592mm
PDS5A8R	36879	500mm	800mm	565mm	1.52mm	679 x 792mm
PDS76STR	38159	700mm	600mm	565mm	1.52mm	706 x 592mm
PDS78STR	38169	700mm	800mm	565mm	1.52mm	706 x 792mm
PDS7A6R	36889	700mm	600mm	565mm	1.52mm	879 x 592mm
PDS7A8R	36899	700mm	800mm	565mm	1.52mm	879 x 792mm

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at www.nvent.com and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE