


# Semiconductor Heaters, DAH

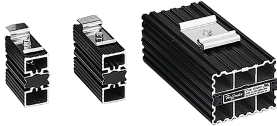

Protect electronic, pneumatic, hydraulic and mechanical equipment from low temperatures, condensation and corrosion with this heater, which maintains a stable enclosure temperature.

## INDUSTRY STANDARDS

---

cURus Component Recognized; File No. E150057

IEC IP54

CE

## FEATURES

---

PTC (Positive Temperature Coefficient) heating element

Mounting clip for 35-mm DIN rails EN 50022

SPECIFICATIONS

**Material:** Aluminum  
**Finish:** Anodized  
**Color:** Black

| Table 1/1      |                |        |       |       |                 |                        |
|----------------|----------------|--------|-------|-------|-----------------|------------------------|
| Catalog Number | Article Number | Height | Width | Depth | Nominal Voltage | Nominal Capacity Watts |
| DAH101         | 70610          | 50mm   | 51mm  | 25mm  | 115V            | 10W                    |
| DAH301         | 70620          | 100mm  | 50mm  | 25mm  | 115V            | 30W                    |
| DAH601         | 15648          | 184mm  | 71mm  | 51mm  | 115V            | 60W                    |

WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.



Our powerful portfolio of brands:

CADDY   ERICO   HOFFMAN   ILSCO   SCHROFF   TRACHTE