


# Inpac Rear Panel With Vented Slots

The rear panel with vented slots can be assembled on to an Inpac Case.

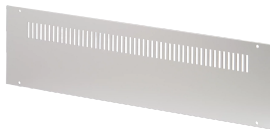

## CERTIFICATIONS



## FEATURES

Rear panel with vented slots for optimized cooling

Al 2.5 mm

## SPECIFICATIONS

|                        |            |
|------------------------|------------|
| <b>Material:</b>       | Aluminum   |
| <b>Finish:</b>         | Anodized   |
| <b>Works With:</b>     | Cases      |
| <b>Product Family:</b> | Inpac      |
| <b>Type:</b>           | Rear Panel |
| <b>Product Type:</b>   | Side Panel |

Table 1/1

| Catalog Number | Rack Height | Package Quantity | Height  | Width | Quick Ship |
|----------------|-------------|------------------|---------|-------|------------|
| 30828-070      | 2U          | 1                | 76mm    | 437mm | No         |
| 30828-082      | 6U          | 1                | 253.8mm | 437mm | No         |

| Catalog Number | Rack Height | Package Quantity | Height  | Width | Quick Ship |
|----------------|-------------|------------------|---------|-------|------------|
| 30828-076      | 4U          | 1                | 165mm   | 437mm | No         |
| 30828-073      | 3U          | 1                | 120.5mm | 437mm | No         |

## ADDITIONAL PRODUCT DETAILS

The scope of delivery of the 19" chassis includes an assembly kit for the front panel.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**