


# Novastar Fan Top Cover

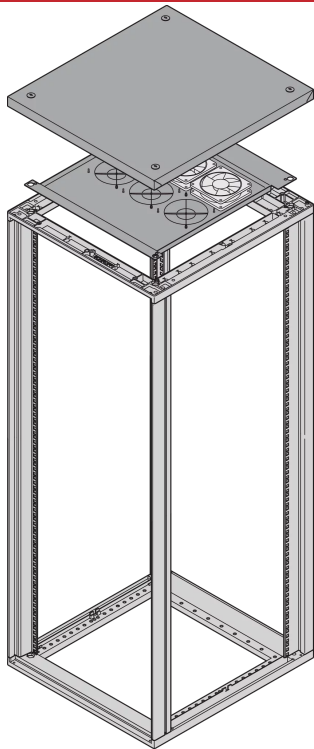

Top covers with fans are compact active cooling units which do not consume rack space. The Novastar fan top cover comes with C14 plug and grounding.

## CERTIFICATIONS



## FEATURES

Connecting cable 0.5 m, IEC C14 plug

St, RAL 7021

Top covers suitable for fan height 25 mm or 38 mm

Incl. grounding and cabling

Fan top cover (33 mm) raised

## SPECIFICATIONS

**Width:** 553mm  
**Product Type:** Cabinet/Rack Top Cover  
**Material:** Steel

Table 1/2

| Catalog Number | Depth  | Package Quantity | Color      | Color Code | Finish        | Type |
|----------------|--------|------------------|------------|------------|---------------|------|
| 27230-081      | 500mm  | 1                | Black Grey | RAL 7021   | Powder Coated | Fan  |
| 27230-083      | 800mm  | 1                | Black Grey | RAL 7021   | Powder Coated | Fan  |
| 27230-085      | 500mm  | 1                | Black Grey | RAL 7021   | Powder Coated | Fan  |
| 27230-086      | 600mm  | 1                | Black Grey | RAL 7021   | Powder Coated | Fan  |
| 27230-087      | 800mm  | 1                | Black Grey | RAL 7021   | Powder Coated | Fan  |
| 27230-082      | 600mm  | 1                | Black Grey | RAL 7021   | Powder Coated | Fan  |
| 27230-094      | 900mm  | 1                | Black Grey | RAL 7021   | Powder Coated | Fan  |
| 27230-095      | 1000mm | 1                | Black Grey | RAL 7021   | Powder Coated | Fan  |
| 27230-096      | 900mm  | 1                | Black Grey | RAL 7021   | Powder Coated | Fan  |
| 27230-097      | 1000mm | 1                | Black Grey | RAL 7021   | Powder Coated | Fan  |

Table 2/2

| Catalog Number | Certifications | Quick Ship |
|----------------|----------------|------------|
| 27230-081      | RoHS, EAC      | No         |
| 27230-083      | RoHS, EAC      | No         |
| 27230-085      | EAC, RoHS      | No         |
| 27230-086      | RoHS, EAC      | No         |

| Catalog Number | Certifications | Quick Ship |
|----------------|----------------|------------|
| 27230-087      | EAC, RoHS      | No         |
| 27230-082      | EAC, RoHS      | No         |
| 27230-094      | RoHS           | No         |
| 27230-095      | RoHS           | No         |
| 27230-096      | RoHS           | No         |
| 27230-097      | RoHS           | No         |

## ADDITIONAL PRODUCT DETAILS

Please order lifting eye separately if required.

Please order any additional fans (for increasing cooling capacity) separately.

If required, please order thermostat or speed controller separately.

## WARNING

nVent products shall be installed and used only as indicated in nVent's product instruction sheets and training materials. Instruction sheets are available at [www.nvent.com](http://www.nvent.com) and from your nVent customer service representative. Improper installation, misuse, misapplication or other failure to completely follow nVent's instructions and warnings may cause product malfunction, property damage, serious bodily injury and death and/or void your warranty.

### North America

All locations  
+1.763.422.2661  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Europe

Straubenhardt, Germany  
+49.7082.794.0  
Betschdorf, France  
+33.3.88.90.64.90  
Warsaw, Poland  
+48.22.209.98.35  
Assago, Italy  
+39.02.932.7141  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Asia

Shanghai, China  
+86.21.2412.6943  
Qingdao, China  
+86.532.8771.6101  
Singapore  
+65.6768.5800  
Shin-Yokohama, Japan  
+81.45.476.0271  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)

### Middle East & India

Dubai, United Arab  
Emirates  
+971.4.378.1700  
Bangalore, India  
+91.80.6715.2001  
Istanbul, Turkey  
+90.216.250.7374  
Chat with us:  
[nvent.com/schroff](http://nvent.com/schroff)



Our powerful portfolio of brands:

**CADDY ERICO HOFFMAN ILSCO SCHROFF TRACHTE**